


# Technical data sheet

Frame cassette for inspection opening, RK, nominal size 250-2, stainless steel  
Item number: 7406004

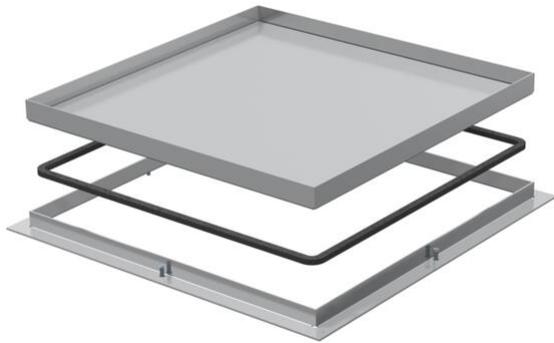

“Blank” frame cassette for the creation of an inspection opening in the UZD250-3 in dry or wet-cleaned floors indoors. Only suitable for smooth floor coverings.



A2 Stainless steel

## Master data


Item number	7406004
Type	RK V2 15
Description 1	Frame cassette
Description 2	blank
Manufacturer	OBO
Dimension	282x282x15
Material	Stainless steel 1.4301
Smallest sales unit	1
Unit of quantity	Piece
Weight	426.8 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	18,6518 kg CO2e / 1 Piece

# Technical data sheet

Frame cassette for inspection opening, RK, nominal size 250-2, stainless steel  
Item number: 7406004



## Dimensions

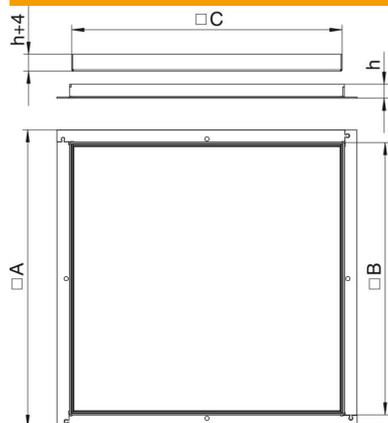

Dimension A	324 mm
Dimension B	288 mm
Dimension C	282 mm
Dimension h	15 mm

## Technical data

Number of cable outlets	0
Cable outlet version	No cable outlet
Floor care	Wet
Suitable for	Underfloor socket structure
Device support to accept mounting boxes	no
Floor covering thickness	13 mm