


Technical data sheet

Frame cassette for inspection opening, RK, nominal size
250-2, stainless steel
Item number: 7406012

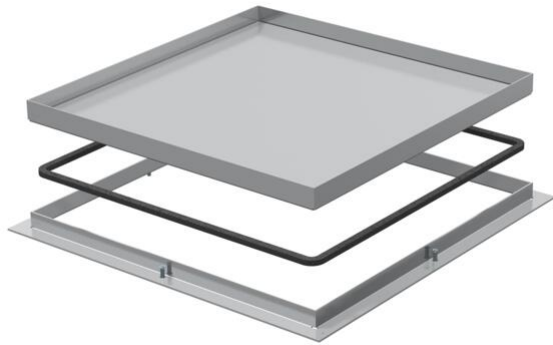

“Blank” frame cassette for the creation of an inspection opening in the UZD250-3 in dry or wet-cleaned floors indoors. Only suitable for smooth floor coverings.



A2 Stainless steel

Master data


Item number	7406012
Type	RK V2 25
Description 1	Frame cassette
Description 2	blank
Manufacturer	OBO
Dimension	282x282x25
Material	Stainless steel 1.4301
Smallest sales unit	1
Unit of quantity	Piece
Weight	458.3 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	20,3499 kg CO2e / 1 Piece

Technical data sheet

Frame cassette for inspection opening, RK, nominal size
250-2, stainless steel
Item number: 7406012



Dimensions

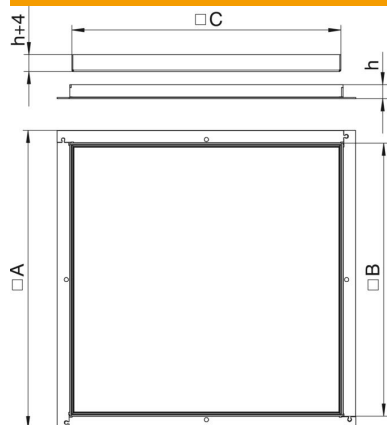

Dimension A	324 mm
Dimension B	288 mm
Dimension C	282 mm
Dimension h	25 mm

Technical data

Number of cable outlets	0
Cable outlet version	No cable outlet
Floor care	Wet
Suitable for	Underfloor socket structure
Device support to accept mounting boxes	no
Floor covering thickness	23 mm