


Technical data sheet

Frame cassette for inspection opening, RK, nominal size 350-3, stainless steel
Item number: 7406040

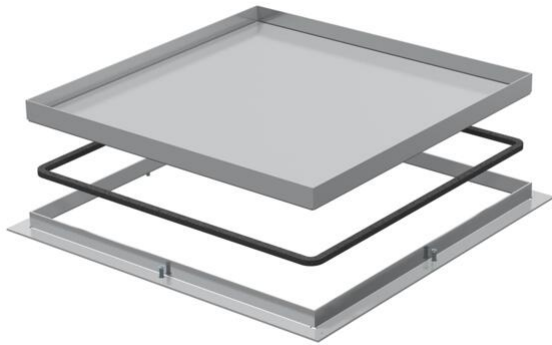

"Blank" frame cassette for the creation of an inspection opening in the UZD350-3 in dry or wet-cleaned floors for indoor use. Only suitable for smooth floor coverings.



A2 Stainless steel

Master data


Item number	7406040
Type	RK V3 25
Description 1	Frame cassette
Description 2	blank
Manufacturer	OBO
Dimension	383x383x25
Material	Stainless steel 1.4301
Smallest sales unit	1
Unit of quantity	Piece
Weight	787 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	31,1781 kg CO2e / 1 Piece

Technical data sheet

Frame cassette for inspection opening, RK, nominal size 350-3, stainless steel
Item number: 7406040



Dimensions

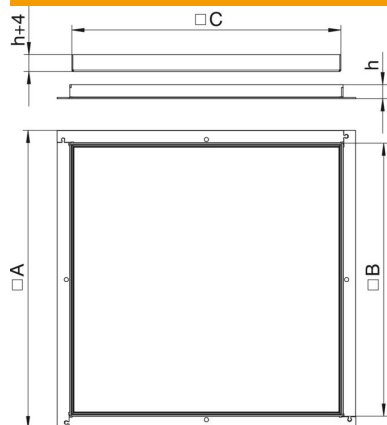

Dimension A	424 mm
Dimension B	388 mm
Dimension C	382 mm
Dimension h	25 mm

Technical data

Number of cable outlets	0
Cable outlet version	No cable outlet
Floor care	Wet
Suitable for	Underfloor socket structure
Device support to accept mounting boxes	no
Floor covering thickness	23 mm