


Technical data sheet

Magic T branch piece 35 FS

Item number: 6041030



T branch piece with quick connector system. For all cable tray types of 35 mm side height.
Fitting in round version. The inner radius of the fitting is 150 mm.

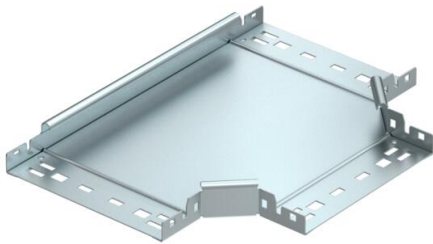

St Steel

FS Strip galvanized

Master data

Item number	6041030
Type	RTM 310 FS
Description 1	T-branch piece
Description 2	with quick connector
Manufacturer	OBO
Dimension	35x100
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	69.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	2,6417 kg CO2e / 1 Piece


Technical data sheet

Magic T branch piece 35 FS

Item number: 6041030



Dimensions

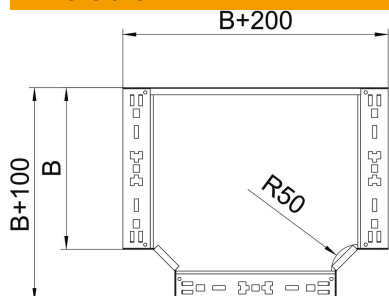

Width	100 mm
Width	4 in
Height	35 mm
Plate thickness	1.25 mm
Dimension B	100 mm

Technical data

Bend (angle)	90°
Connector version	Integrated connector
Maintain electrical functions	no
NATO hole pattern	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Wide-span version	no
Type of connector, cable support system	Screwed
Rail thickness	1.25 mm