


Technical data sheet

Magic T branch piece 35 FS

Item number: 6041034



T branch piece with quick connector system. For all cable tray types of 35 mm side height.
Fitting in round version. The inner radius of the fitting is 150 mm.

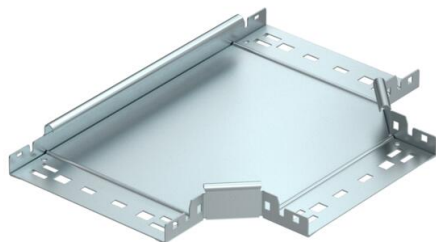

St Steel

FS Strip galvanized

Master data

| | |
|---------------------|----------------------|
| Item number | 6041034 |
| Type | RTM 330 FS |
| Description 1 | T-branch piece |
| Description 2 | with quick connector |
| Manufacturer | OBO |
| Dimension | 35x300 |
| Material | Steel |
| Surface | Strip galvanized |
| Surface standard | DIN EN 10346 |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 216.6 kg |
| Weight unit | kg/100 pc. |


Technical data sheet

Magic T branch piece 35 FS

Item number: 6041034



Dimensions

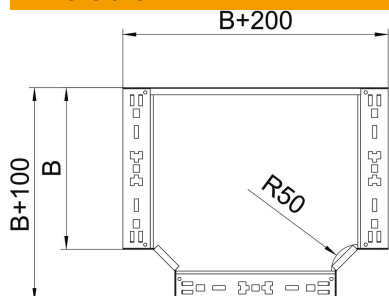

| | |
|-----------------|---------|
| Width | 300 mm |
| Width | 12 in |
| Height | 35 mm |
| Plate thickness | 1.25 mm |
| Dimension B | 300 mm |

Technical data

| | |
|---|----------------------|
| Bend (angle) | 90° |
| Connector version | Integrated connector |
| Maintain electrical functions | no |
| NATO hole pattern | no |
| Change of direction | Horizontal |
| Rustproof steel, pickled | no |
| Wide-span version | no |
| Type of connector, cable support system | Screwed |
| Rail thickness | 1.25 mm |