


# Technical data sheet

## Magic tee 60FS

Item number: 6041326



Tee branch piece with quick connector system. For all cable tray types of 60 mm side height.

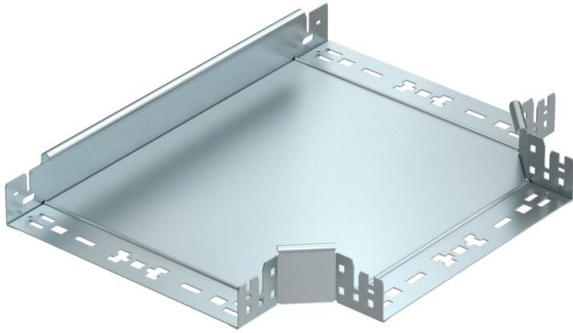

- St** Steel
- FS** Strip galvanized

### Master data

Item number	6041326
Type	RTM 630 FS
Description 1	T-branch piece
Description 2	with quick connector
Manufacturer	OBO
Dimension	60x300
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	228.42 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	7,0802 kg COe / 1 Piece


# Technical data sheet

## Magic tee 60FS

Item number: 6041326



### Dimensions

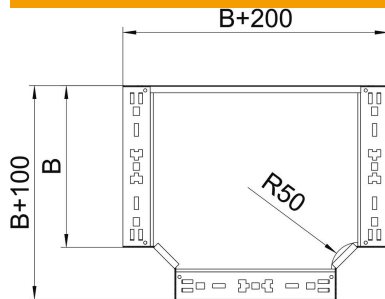

Width	300 mm
Width	12 in
Height	60 mm
Plate thickness	1.25 mm
Dimension B	300 mm

### Technical data

Bend (angle)	90°
Connector version	Integrated connector
Maintain electrical functions	yes
NATO hole pattern	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Wide-span version	no
Type of connector, cable support system	Screwed
Rail thickness	1.25 mm