


Technical data sheet

Magic tee 60FS

Item number: 6041328



Tee branch piece with quick connector system. For all cable tray types of 60 mm side height.

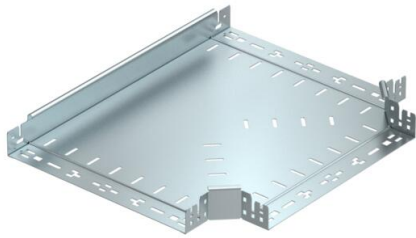

- St** Steel
- FS** Strip galvanized

Master data

Item number	6041328
Type	RTM 640 FS
Description 1	T-branch piece
Description 2	with quick connector
Manufacturer	OBO
Dimension	60x400
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	335.6 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	11,9834 kg COe / 1 Piece


Technical data sheet

Magic tee 60FS

Item number: 6041328



Dimensions

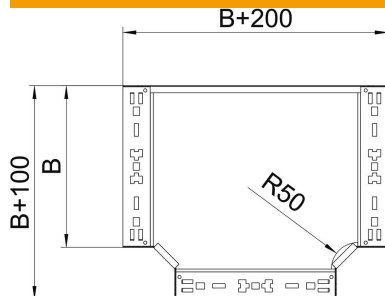

Width	400 mm
Width	16 in
Height	60 mm
Plate thickness	1.25 mm
Dimension B	400 mm

Technical data

Bend (angle)	90°
Connector version	Integrated connector
Maintain electrical functions	yes
NATO hole pattern	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Wide-span version	no
Type of connector, cable support system	Screwed
Rail thickness	1.25 mm