


# Technical data sheet

## Magic tee 85 FT

Item number: 6041684



Tee with quick connector system. For all cable tray types of 85 mm side height.

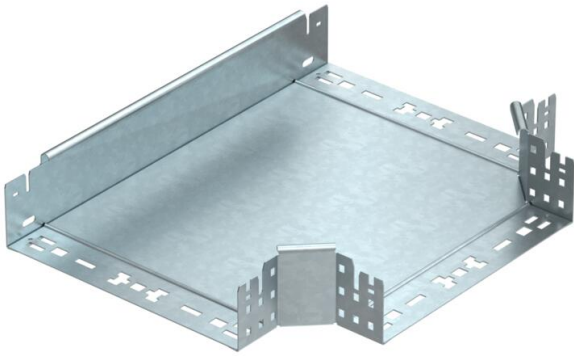

- St** Steel
- FT** Hot-dip galvanised

### Master data

|                     |                      |
|---------------------|----------------------|
| Item number         | 6041684              |
| Type                | RTM 830 FT           |
| Description 1       | T-branch piece       |
| Description 2       | with quick connector |
| Manufacturer        | OBO                  |
| Dimension           | 85x300               |
| Material            | Steel                |
| Surface             | Hot-dip galvanised   |
| Surface standard    | DIN EN ISO 1461      |
| Smallest sales unit | 1                    |
| Unit of quantity    | Piece                |
| Weight              | 274.3 kg             |
| Weight unit         | kg/100 pc.           |


# Technical data sheet

## Magic tee 85 FT

Item number: 6041684



### Dimensions

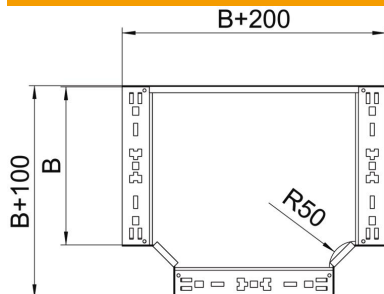

|                 |         |
|-----------------|---------|
| Width           | 300 mm  |
| Height          | 85 mm   |
| Plate thickness | 1.25 mm |
| Dimension B     | 300 mm  |

### Technical data

|   |                      |
|---|----------------------|
| Bend (angle)                            | 90°                  |
| Connector version                       | Integrated connector |
| Maintain electrical functions           | no                   |
| NATO hole pattern                       | no                   |
| Change of direction                     | Horizontal           |
| Rustproof steel, pickled                | no                   |
| Wide-span version                       | no                   |
| Type of connector, cable support system | Screwed              |
| Rail thickness                          | 1.25 mm              |