


Technical data sheet

T branch piece 110 FS

Item number: 7003714

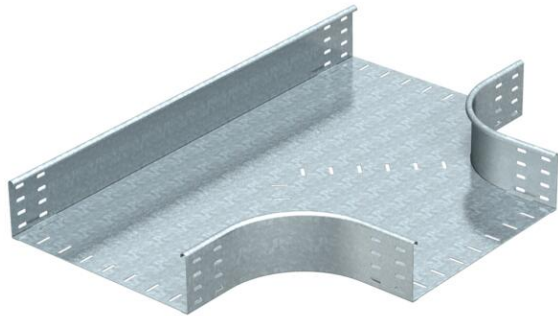

Horizontal T branch piece, for all cable tray types of 110 mm side height.
Fastening materials should be ordered separately.




- St** Steel
- FS** Strip galvanized

Master data

Item number	7003714
Type	RT 150 FS
Description 1	T-branch piece
Description 2	horizontal, round type
Manufacturer	OBO
Dimension	110x500
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	950 kg
Weight unit	kg/100 pc.

Dimensions

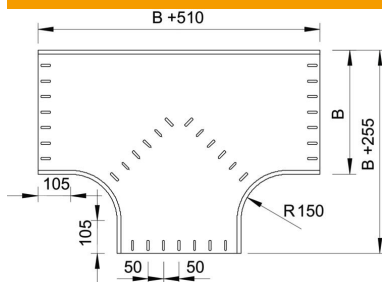

Width	500 mm
Width	20 in
Height	110 mm
Dimension B	500 mm
Dimension R	150 mm

Technical data sheet

T branch piece 110 FS

Item number: 7003714



Technical data

Bend (angle)	90°
Connector version	Without connectors
Maintain electrical functions	no
NATO hole pattern	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Wide-span version	no
Type of connector, cable support system	Screwed
Rail thickness	1.25 mm