


# Technical data sheet

## T piece 110/600 A2

Item number: 6038370



T piece for the creation of a horizontal branch, fitting for lock and screw-on cable trays of side height 110 mm. Screwless mounting with double clamps or screw connection with FRS truss-head screws and M6 combination nuts. Can be used indoors and outdoors. Fastening material must be ordered separately.

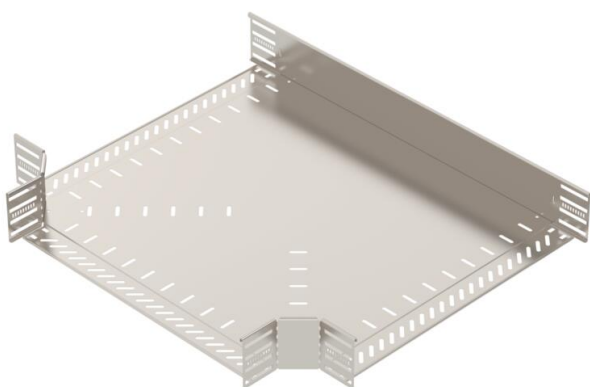

**A2** Stainless steel

**2B** Bright, treated

### Master data

Item number	6038370
Type	RT 160 A2
Description 1	T piece
Description 2	for cable tray, horizontal
Manufacturer	OBO
Dimension	110x600
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	566.4 kg
Weight unit	kg/100 pc.


# Technical data sheet

## T piece 110/600 A2

Item number: 6038370



### Dimensions

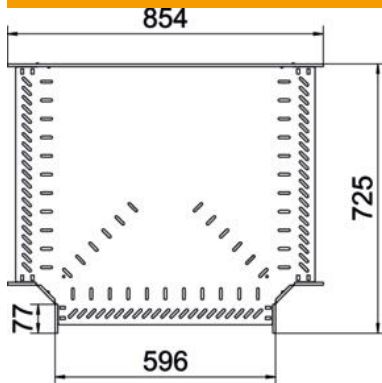

Width	600 mm
Height	110 mm
Plate thickness	1 mm
Dimension B	600 mm

### Technical data

Connector version	Integrated connector
Maintain electrical functions	no
NATO hole pattern	no
Rustproof steel, pickled	no
Permitted temperature range, max.	120 °C
Permitted temperature range, min.	-20 °C
Wide-span version	no
Type of connector, cable support system	screwed/clamped
Recommended quantity of bolts	36 St.
Rail thickness	1.25 mm