


Technical data sheet

Reducer/stop-end 60 A2

Item number: 7109857

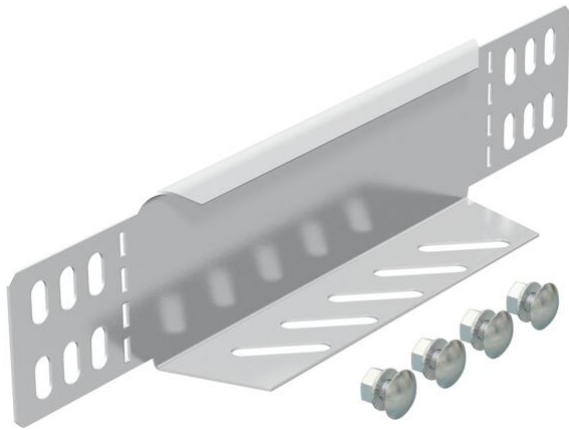

Reducer/stop-end plate for cable trays with side height 60 mm. From a width of 150 mm, a perforated lower flange is available.

Including appropriate fastening material.




A2 Stainless steel

2B Bright, treated

Master data

| | |
|------------------------------------|-----------------------------|
| Item number | 7109857 |
| Type | RWEB 630 A2 |
| Description 1 | Reducer profile/end closure |
| Description 2 | for cable tray |
| Manufacturer | OBO |
| Dimension | 60x300 |
| Colour | stainless steel |
| Material | Stainless steel 1.4301 |
| Surface | Bright, treated |
| Surface standard | |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 31.2 kg |
| Weight unit | kg/100 pc. |
| CO2 Footprint (GWP) Cradle-to-Gate | 1,9945 kg CO2e / 1 Piece |

Dimensions

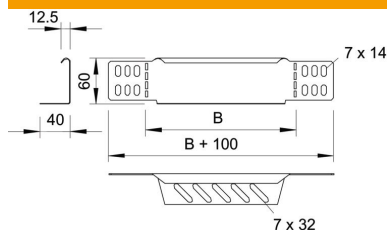

| | |
|-----------------|--------|
| Width | 300 mm |
| Width | 12 in |
| Height | 60 mm |
| Height | 2 in |
| Plate thickness | 1 mm |
| Dimension B | 300 mm |

Technical data sheet

Reducer/stop-end 60 A2

Item number: 7109857



Technical data

| | |
|-------------------------------|----|
| Maintain electrical functions | no |
| Rustproof steel, pickled | no |