

# Technical data sheet

## Reducer/stop-end 60 A2

Item number: 7109938



Reducer/stop-end plate for cable trays with side height 60 mm. From a width of 150 mm, a perforated lower flange is available.

Including appropriate fastening material.




**A2** Stainless steel

**2B** Bright, treated

### Master data

|                                    |                             |
|------------------------------------|-----------------------------|
| Item number                        | 7109938                     |
| Type                               | RWEB 660 A2                 |
| Description 1                      | Reducer profile/end closure |
| Description 2                      | for cable tray              |
| Manufacturer                       | OBO                         |
| Dimension                          | 60x600                      |
| Colour                             | stainless steel             |
| Material                           | Stainless steel 1.4301      |
| Surface                            | Bright, treated             |
| Surface standard                   |                             |
| Smallest sales unit                | 1                           |
| Unit of quantity                   | Piece                       |
| Weight                             | 56.1 kg                     |
| Weight unit                        | kg/100 pc.                  |
| CO2 Footprint (GWP) Cradle-to-Gate | 3,524 kg CO2e / 1 Piece     |

### Dimensions

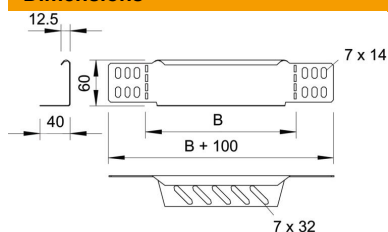

|                 |        |
|-----------------|--------|
| Width           | 600 mm |
| Width           | 24 in  |
| Height          | 60 mm  |
| Height          | 2 in   |
| Plate thickness | 1 mm   |
| Dimension B     | 600 mm |

# Technical data sheet

Reducer/stop-end 60 A2

Item number: 7109938



## Technical data

|                               |    |
|-------------------------------|----|
| Maintain electrical functions | no |
| Rustproof steel, pickled      | no |