


Technical data sheet

Electrogalvanised steel pipe, without thread

Item number: 2046840



Electrical installation pipe without threaded ends according to EN 61386-1 for mechanical protection of cables. With burr-free inner wall.

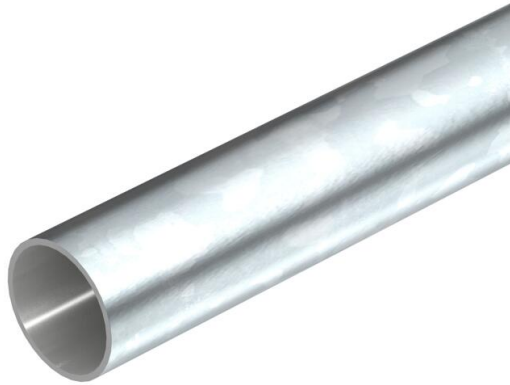

St	Steel
G	Electrogalvanized

Master data

Item number	2046840
Type	S16W G
Description 1	Plug-in conduit
Description 2	without thread
Manufacturer	OBO
Dimension	Ø16, 3000mm
Material	Steel
Surface	Electrogalvanized
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	30
Unit of quantity	Metre
Weight	37 kg
Weight unit	kg/100 m
CO Footprint (GWP) Cradle-to-Gate	0,7384 kg COe / 1 Meter

Technical data sheet

Electrogalvanised steel pipe, without thread

Item number: 2046840



Dimensions



Length	3,000 mm
Dimension D	16 mm
Dimension L	3,000 mm
Dimension m (mm)	M16
Dimension t	1 mm



Technical data sheet

Electrogalvanised steel pipe, without thread

Item number: 2046840



Technical data

Surface-mounted	yes
Pipe version	Rigid without thread
Concrete installation	yes
Bending behaviour	rigid
Pressure resistance	Heavy (1,250 N)
Use temperature, max.	+ 400 °C
Use temperature, min.	- 45 °C
Cavity wall installation	yes
Installation on wood	yes
Installation in the earth	no
Installation outdoors	no
Classification code	44571
Machines and system installation	no
With sleeve	no
Brushed surface	no
Polished surface	no
Impact resistance	Heavy (2.0 kg/300 mm)
Permitted temperature range, max.	400 °C
Permitted temperature range, min.	-45 °C
Underfloor installation (bitumen, hot asphalt)	yes
Underfloor installation (screed)	yes
Concealed	yes