

Technical data sheet

Terrazzo lined body for height-adjustable cassettes, nominal size 4

Item number: 7404380



Lined body, suitable for polishing, for the direct and jointless installation of height-adjustable cassettes, nominal size 4, into surface-finished screeds/terrazzo floorings. The casing is laid floatingly onto underfloor boxes with mounting lids of nominal size 4, closing the gaps between underfloor box and cassette frame. The protection cover made from aluminium sheet is put into the cassette frame as a dummy before the screed work is done and can be polished over with the screed or terrazzo.



| | |
|----|------------------|
| St | Steel |
| FS | Strip galvanized |

Master data

| | |
|------------------------------------|-------------------------------|
| Item number | 7404380 |
| Type | SK RK4 |
| Description 1 | Shuttering unit for cassettes |
| Description 2 | for polished screeds |
| Manufacturer | OBO |
| Dimension | 253x253x55 |
| Material | Steel |
| Surface | Strip galvanized |
| Surface standard | DIN EN 10346 |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 135.5 kg |
| Weight unit | kg/100 pc. |
| CO2 Footprint (GWP) Cradle-to-Gate | 6,2323 kg CO2e / 1 Piece |


Technical data sheet

Terrazzo lined body for height-adjustable cassettes, nominal size 4

Item number: 7404380



Dimensions

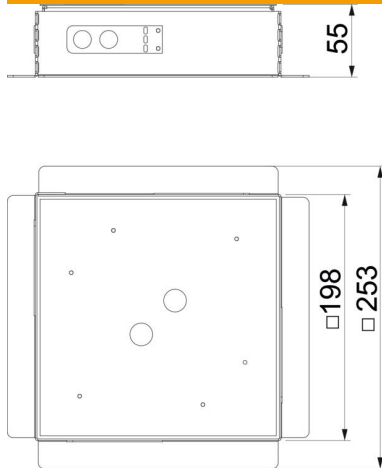

| | |
|-------------|--------|
| Length | 198 mm |
| Width | 198 mm |
| Height | 55 mm |
| Dimension a | 198 mm |
| Dimension A | 253 mm |
| Dimension h | 55 mm |

Technical data

| | |
|--|--------|
| Shape | Square |
| Floor height, max. | 200 mm |
| Floor height, min. | 130 mm |
| Nominal size for device installation units | 4 |