

Technical data sheet

Industrial vertical cable ladder, 6 m C40

Item number: 6013481



Vertical ladder of side height 80 mm with screwed-in rungs.
The vertical ladder is shipped in an unmounted state.
The appropriate clamp clip is type 2056U.



St	Steel
FT	Hot-dip galvanised

Master data

Item number	6013481
Type	SLS 80 C40 12 FT
Description 1	Vertical ladder industrial
Description 2	with C 40 rung
Manufacturer	OBO
Dimension	1200x6000
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	6
Unit of quantity	Metre
Weight	1553.333 kg
Weight unit	kg/100 m


Technical data sheet

Industrial vertical cable ladder, 6 m C40

Item number: 6013481



Dimensions

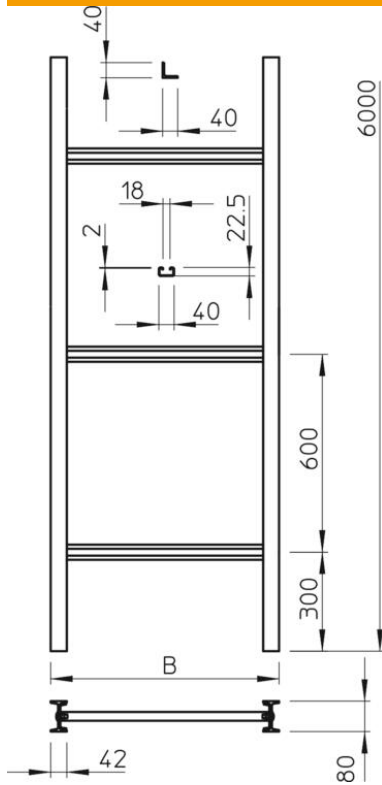

Length	6,000 mm
Width	1,200 mm
Height	80 mm
Dimension B	1,200 mm
Rung slot dimension	18.00

Technical data

Side wall version	I profile
Version of the rungs	Profile unperforated
Maintain electrical functions	no
Rustproof steel, pickled	no
Side perforation	yes
Rung distance	600 mm