

# Technical data sheet

## Ceiling profile clamp, with threaded bolt

Item number: 1488601



Ceiling profile clamp with threaded bolt for individual mounting solutions on suspended ceilings. Suitable for support profiles with a width of 25 mm, fastening by clamping



|    |           |
|----|-----------|
| St | Steel     |
| ZL | Zinc slat |

### Master data

|                     |                       |
|---------------------|-----------------------|
| Item number         | 1488601               |
| Type                | SPC M6x9              |
| Description 1       | Ceiling profile clamp |
| Description 2       | with threaded bolt    |
| Manufacturer        | OBO                   |
| Dimension           | M6x9mm                |
| Colour              | zinc                  |
| Material            | Steel                 |
| Surface             | Zinc slat             |
| Surface standard    |                       |
| Smallest sales unit | 100                   |
| Unit of quantity    | Piece                 |
| Weight              | 1 kg                  |
| Weight unit         | kg/100 pc.            |


 
# Technical data sheet

## Ceiling profile clamp, with threaded bolt

Item number: 1488601



### Dimensions

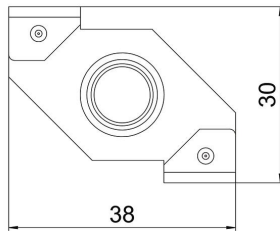

|             |       |
|-------------|-------|
| Length      | 38 mm |
| Width       | 30 mm |
| Height      | 16 mm |
| Dimension H | 16 mm |

### Technical data

|                           |         |
|---------------------------|---------|
| Connection type/component | Thread  |
| Fastening type            | Clamp   |
| Breaking load             | 0.22 kN |
| Flange thickness F max.   | 1.5 mm  |
| Flange thickness F min.   | 1 mm    |
| Thread                    | M6x9    |
| Thread metric             | 6       |
| Hinge, adjustable         | no      |
| Hinged                    | no      |