

Technical data sheet

Rung C30, perforated FT

Item number: 6009987



Perforated rung, C profile version, for subsequent installation and use in cable ladders. To be screwed on. Fastening material must be ordered separately.



- St** Steel
- FT** Hot-dip galvanised

Master data

Item number	6009987
Type	SPR C30 595 FT
Description 1	Rung, perforated
Description 2	material thickness 1.5mm
Manufacturer	OBO
Dimension	L=595mm
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1500
Unit of quantity	Piece
Weight	41.6 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,0097 kg CO2e / 1 Piece


Technical data sheet

Rung C30, perforated FT

Item number: 6009987



Dimensions

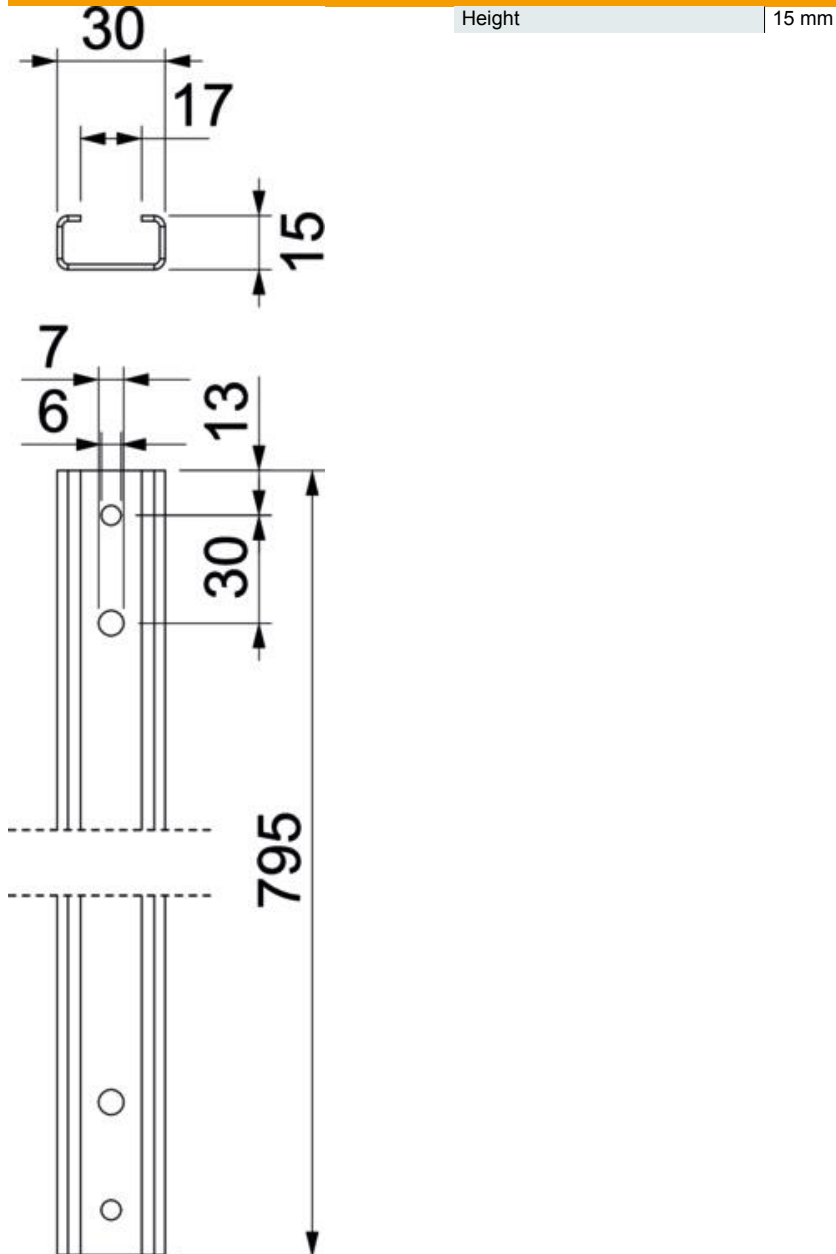

Technical data

Slot width	17 mm
------------	-------