

Technical data sheet

starQuick clip

Item number: 2146258



Highly stable clip to accept plastic and metal electrical and sanitary pipes, as well as the Quick Pipe electrical installation pipe. Universal fastening options on walls, ceilings and steel structures, both indoors and outdoors. Flexible clamping range of several millimetres. Toolless pipe mounting. Can be arranged to up to Ø 28 mm, also with OBO Quick starQuick clip. For high load values, can be combined with double bracket. Can be mounted on profile rails for variable spacings and numbers of clips.



PA Polyamide

Master data

| | |
|---------------------|----------------------|
| Item number | 2146258 |
| Type | SQ-32 LGR |
| Description 1 | starQuick clip |
| Manufacturer | OBO |
| Dimension | 31,2-35,8mm |
| Colour | Light grey; RAL 7035 |
| Material | Polyamide |
| Smallest sales unit | 50 |
| Unit of quantity | Piece |
| Weight | 1.23 kg |
| Weight unit | kg/100 pc. |


Technical data sheet

starQuick clip

Item number: 2146258



Dimensions

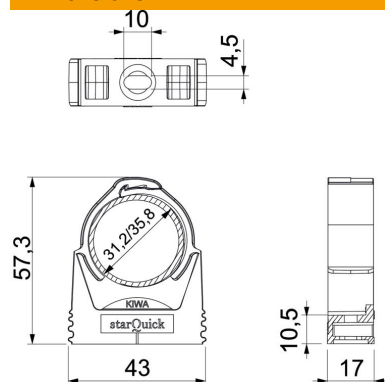

| | |
|-------------|---------|
| Dimension A | 43 mm |
| Dimension B | 17 mm |
| Dimension E | 10 mm |
| Dimension F | 4.5 mm |
| Dimension h | 10.5 mm |
| Dimension H | 57.3 mm |

Technical data

| | |
|-------------------------|---|
| Expandable | yes |
| Number of cables/pipes | 1 |
| Fastening type | Screw hole |
| Breaking load | 1 kN |
| Flame-resistant | acc. to VDE 0471/DIN 695 Part 2-1, test temperature 650°C |
| Closed | yes |
| Halogen-free | yes |
| With inlay | no |
| Nominal size | 32-35 |
| Snap system | yes |
| Quick clip installation | Duchgangsloch mit starQuick-Mutter M6 oder M8 |
| Clamping range D, max. | 35.8 mm |
| Clamping range D, min. | 31.2 mm |
| UV-resistant | yes |