

# Technical data sheet

## starQuick clip

Item number: 2146320



Highly stable clip to accept plastic and metal electrical and sanitary pipes, as well as the Quick Pipe electrical installation pipe. Universal fastening options on walls, ceilings and steel structures, both indoors and outdoors. Flexible clamping range of several millimetres. Toolless pipe mounting. Can be arranged to up to Ø 28 mm, also with OBO Quick starQuick clip. For high load values, can be combined with double bracket. Can be mounted on profile rails for variable spacings and numbers of clips.



PA Polyamide

### Master data

Item number	2146320
Type	SQ-40 LGR
Description 1	starQuick clip
Manufacturer	OBO
Dimension	39,3-44,5mm
Colour	Light grey; RAL 7035
Material	Polyamide
Smallest sales unit	25
Unit of quantity	Piece
Weight	1.71 kg
Weight unit	kg/100 pc.


# Technical data sheet

## starQuick clip

Item number: 2146320



### Dimensions

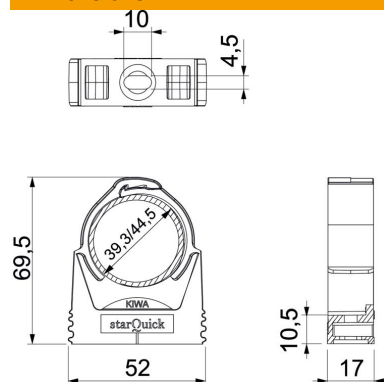

Dimension A	52 mm
Dimension B	17 mm
Dimension E	10 mm
Dimension F	4.5 mm
Dimension h	10.5 mm
Dimension H	69.5 mm

### Technical data

Expandable	yes
Number of cables/pipes	1
Fastening type	Screw hole
Breaking load	1.2 kN
Flame-resistant	acc. to VDE 0471/DIN 695 Part 2-1, test temperature 650°C
Closed	yes
Halogen-free	yes
With inlay	no
Nominal size	40-44
Snap system	yes
Quick clip installation	Duchgangsloch mit starQuick-Mutter M6 oder M8
Clamping range D, max.	44.5 mm
Clamping range D, min.	39.3 mm
UV-resistant	yes