

Technical data sheet

0° socket, protective contact, double

Item number: 6119740



Protective contact socket, double 0°, with increased touch protection, with screwless terminals, 2-pin, 16 A, 250 V~, with connection terminals according to IEC 60884-1.



Polycarbonate Eco

Matt

Master data		
Item number	6119740	
Type	STD-D0N AL2	
Description 1	Socket 0°, double	
Description 2	protective contact	
Manufacturer	OBO	
Dimension	90x45x42	
Colour	Aluminium painted	
Material	Polycarbonate Eco	
Surface	Matt	
Surface standard		
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	6.46 kg	
Weight unit	kg/100 pc.	


Technical data sheet

0° socket, protective contact, double

Item number: 6119740



Dimensions

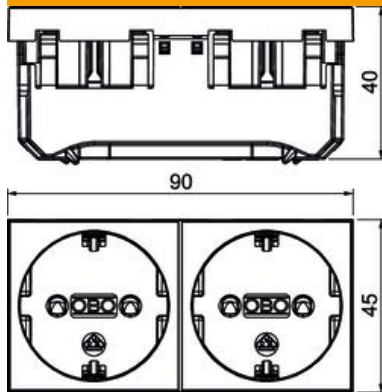

Width	90 mm
Height	45 mm

Technical data

Cover	Central plate
Closable	no
Connection type	Screwless terminal
Number of units	2
Number of modules (for modular construction)	0
Number of switchable sockets	0
Number of poles	2
Printed label/coding	Without printing
Version for	Double 0°
Surface version	Matt
Version for	SCHUKO
Ejection mechanism	no
Fastening type	Lock
Labelling panel	no
Operating temperature, max.	40 °C
Operating temperature, min.	-5 °C
increased touch protection	yes
Error current protection	no
For more difficult conditions (according to VDE)	no
Power reserve	no
Halogen-free	yes
Insulated installation	no
Hinged cover	no
Coding	no
Warning light	no
With on/off switch	no
With fine-wire fuse	no
With functional lighting	no
With orientation lighting	no
Mounting type	Device installation duct
Nominal voltage	250 V
Nominal current	16 A
Protection rating	Other

Technical data sheet

0° socket, protective contact, double

Item number: 6119740



Technical data

Special power supply	Without special power supply
Socket version	Protective contact
Socket angle	0°
Transparent	no
Rotated central insert	no
Surge protection	no