

Technical data sheet

33° socket, with earthing pin, encoded version, double

Item number: 6120324



Socket with earthing pin Double 33°, encoded version, with increased touch protection, with screwless terminals, 2-pin, 16 A, 250 V~, with connection terminals to IEC 60884-1. The socket can only be used in conjunction with an encoding pin, type CST-STD.
Note: The encoding pin is not contained in the scope of supply.
For installation in Rapid 45 trunking, device installation trunking, service poles, underfloor systems and desk boxes.



PC Polycarbonate

Master data		
Item number	6120324	
Type	STD-F3K SRO2	
Description 1	Socket 33°, double, coded	
Description 2	with earth pin	
Manufacturer	OBO	
Dimension	250V, 10/16A	
Colour	Signal red; RAL 3001	
Material	Polycarbonate	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	7.5 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,3477 kg COe / 1 Piece	


Technical data sheet

33° socket, with earthing pin, encoded version, double


Item number: 6120324



Dimensions

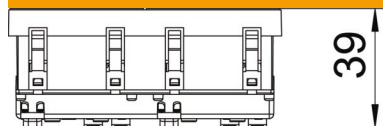

Width	90 mm
Height	45 mm

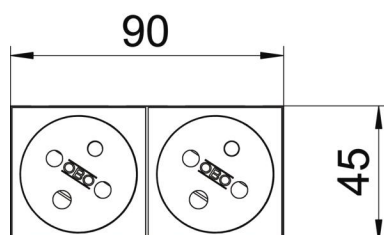

Technical data

Cover	Central plate
Closable	no
Connection type	Screwless terminal
Number of units	2
Number of modules (for modular construction)	0
Number of switchable sockets	0
Number of poles	2
Printed label/coding	Without printing
Version for	Double 33°
Surface version	Matt
Version for	Protective contact pin
Ejection mechanism	no
Fastening type	Lock
Labelling panel	no
Operating temperature, max.	40 °C
Operating temperature, min.	-5 °C
increased touch protection	yes
Error current protection	no
For more difficult conditions (according to VDE)	no
Halogen-free	yes
Insulated installation	no
Hinged cover	no
Coding	yes
Warning light	no
With on/off switch	no
With fine-wire fuse	no
With functional lighting	no
With orientation lighting	no
Mounting type	Device installation duct
Nominal voltage	250 V

Technical data sheet

33° socket, with earthing pin, encoded version, double

Item number: 6120324



Technical data

Nominal current	16 A
Protection rating	Other
Special power supply	Without special power supply
Socket version	NF
Socket angle	33°
Depth	39 mm
Transparent	no
Rotated central insert	yes
Surge protection	no