

Technical data sheet

Hot-dip galvanised steel sleeve, without thread

Item number: 2046623



Accessory part: plug-in sleeve for the connections between electrical installation pipes. With burr-free inner wall.



- St** Steel
- FT** Hot-dip galvanised

Master data

Item number	2046623
Type	SV32W FT
Description 1	Conduit plug-in coupler
Description 2	without thread
Manufacturer	OBO
Dimension	Ø32mm
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	50
Unit of quantity	Piece
Weight	7.5 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,2804 kg CO2e / 1 Piece


Technical data sheet

Hot-dip galvanised steel sleeve, without thread

Item number: 2046623



Dimensions

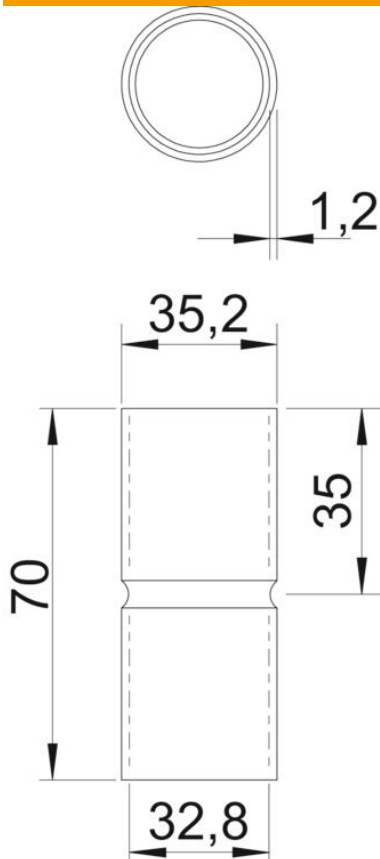

Length	70 mm
Dimension D	35.2 mm
Dimension d	32.8 mm
Dimension L	70 mm
Dimension l	35 mm
Dimension m (mm)	M32
Dimension t	1.2 mm

Technical data

Version for for pipe diameter	Connector 32 mm
Size	32
Halogen-free	yes
With inspection opening and lid	no
Brushed surface	no
Polished surface	no
Permitted temperature range, max.	400 °C
Permitted temperature range, min.	-45 °C
Two-part	no