

# Technical data sheet

## Hot-dip galvanised steel sleeve, without thread

Item number: 2046625



Accessory part: plug-in sleeve for the connections between electrical installation pipes. With burr-free inner wall.



- St** Steel
- FT** Hot-dip galvanised

### Master data

Item number	2046625
Type	SV50W FT
Description 1	Conduit plug-in coupler
Description 2	without thread
Manufacturer	OBO
Dimension	Ø50mm
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	10
Unit of quantity	Piece
Weight	22 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,5613 kg CO2e / 1 Piece


# Technical data sheet

## Hot-dip galvanised steel sleeve, without thread

Item number: 2046625



### Dimensions

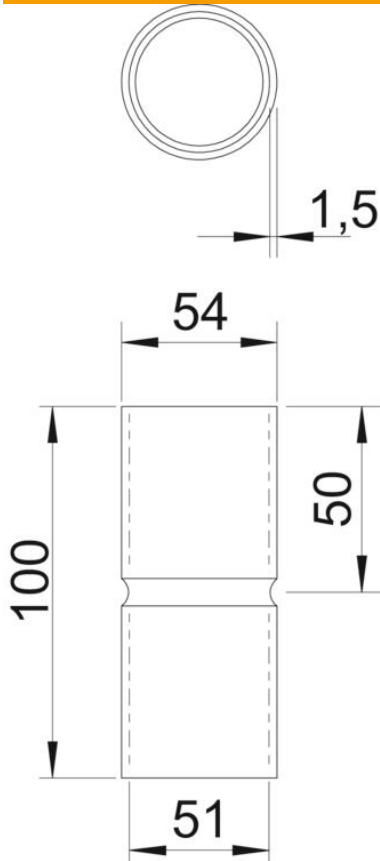

Length	100 mm
Dimension D	54 mm
Dimension d	51 mm
Dimension L	100 mm
Dimension l	50 mm
Dimension m (mm)	M50
Dimension t	1.5 mm

### Technical data

Version for for pipe diameter	Connector 50 mm
Size	50
Halogen-free	yes
With inspection opening and lid	no
Brushed surface	no
Polished surface	no
Permitted temperature range, max.	400 °C
Permitted temperature range, min.	-45 °C
Two-part	no