

Technical data sheet

Stainless steel sleeve V4A

Item number: 2046776



Accessory part: plug-in sleeve for the connections between electrical installation pipes. With burr-free inner wall.



A4 Stainless steel

2B Bright, treated

Master data

Item number	2046776
Type	SV63W A4
Description 1	Stainl.steel connection sleeve
Description 2	without thread
Manufacturer	OBO
Dimension	Ø63mm
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	3
Unit of quantity	Piece
Weight	20.9 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	1,1513 kg COe / 1 Piece


Technical data sheet

Stainless steel sleeve V4A

Item number: 2046776



Dimensions

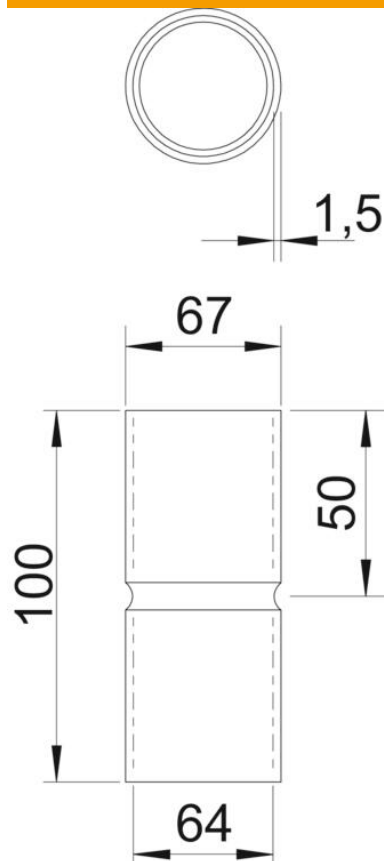

Length	100 mm
Dimension D	65.8 mm
Dimension d	63.2 mm
Dimension L	100 mm
Dimension I	50 mm
Dimension m (mm)	M63
Dimension t	1.3 mm

Technical data

Version for for pipe diameter	Connector 63 mm
Size	63
Halogen-free	yes
With inspection opening and lid	no
Brushed surface	yes
Polished surface	no
Permitted temperature range, max.	400 °C
Permitted temperature range, min.	-45 °C
Two-part	no