

# Technical data sheet

## Hot-dip galvanised steel sleeve, without thread

Item number: 2046626



Accessory part: plug-in sleeve for the connections between electrical installation pipes. With burr-free inner wall.



- St** Steel
- FT** Hot-dip galvanised

### Master data

Item number	2046626
Type	SV63W FT
Description 1	Conduit plug-in coupler
Description 2	without thread
Manufacturer	OBO
Dimension	Ø63mm
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	5
Unit of quantity	Piece
Weight	22 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,7433 kg CO2e / 1 Piece


# Technical data sheet

## Hot-dip galvanised steel sleeve, without thread

Item number: 2046626



### Dimensions

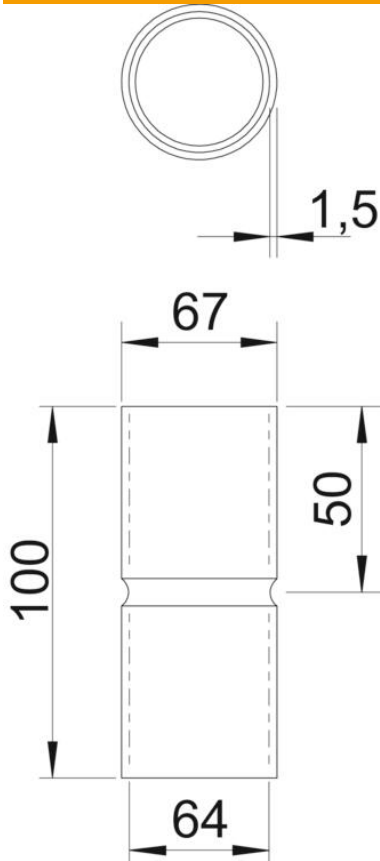

Length	100 mm
Dimension D	67 mm
Dimension d	63 mm
Dimension L	100 mm
Dimension l	50 mm
Dimension m (mm)	M63
Dimension t	1.5 mm

### Technical data

Version for pipe diameter	63 mm
Size	63
Halogen-free	yes
With inspection opening and lid	no
Brushed surface	no
Polished surface	no
Permitted temperature range, max.	400 °C
Permitted temperature range, min.	-45 °C
Two-part	no