


# Technical data sheet

Cover plate, Telitank T12L, blank, for lengthwise side

Item number: 7408140



Cover plate "blank", suitable for lengthwise side of T12L (1/3 cover).

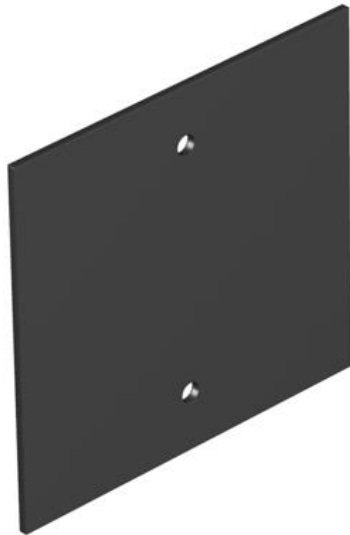

**PVC** Polyvinylchloride

## Master data

|                     |                          |
|---------------------|--------------------------|
| Item number         | 7408140                  |
| Type                | T12L P05S 9011           |
| Description 1       | Cover plate              |
| Description 2       | blank for T12L           |
| Manufacturer        | OBO                      |
| Dimension           | 94.5x88mm                |
| Colour              | Graphite black; RAL 9011 |
| Material            | Polyvinylchloride        |
| Smallest sales unit | 1                        |
| Unit of quantity    | Piece                    |
| Weight              | 2.15 kg                  |
| Weight unit         | kg/100 pc.               |


# Technical data sheet

Cover plate, Telitank T12L, blank, for lengthwise side

Item number: 7408140



## Dimensions

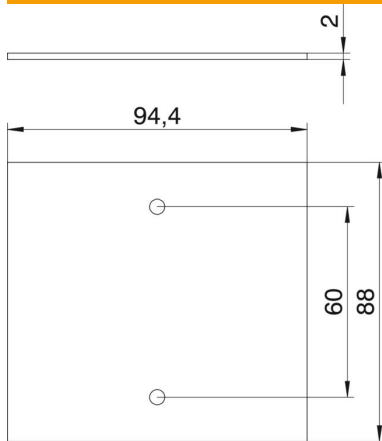

|        |       |
|--------|-------|
| Length | 88 mm |
| Width  | 95 mm |
| Height | 2 mm  |

## Technical data

|                                |               |
|--------------------------------|---------------|
| Application                    | On-floor tank |
| Number of CEE/Perilex openings | 0             |
| Number of triple openings      | 0             |
| Number of single openings      | 0             |
| Number of oval openings        | 0             |
| Number of square openings      | 0             |
| Number of round openings       | 0             |
| Number of double openings      | 0             |
| Fastening type                 | Screw-on      |
| Labelling panel                | no            |
| Blanking lid                   | yes           |
| Seal installation option       | no            |
| Suitable for labelling panel   | no            |
| Installation technology        | Miscellaneous |