

Technical data sheet

Cover plate, Telitank T12L, round installation opening for EKR device

Item number: 7408172



Cover plate with 1 perforation (Ø 45 mm) for one accessory with support ring or bracket, suitable for T12L lengthwise side (1/4 cover) or for T12L narrow side (1/2 cover).



PVC Polyvinylchloride

Master data

Item number	7408172
Type	T12L P1S 9011
Description 1	Cover plate
Description 2	1x EK for T12L
Manufacturer	OBO
Dimension	71x88mm
Colour	Graphite black; RAL 9011
Material	Polyvinylchloride
Smallest sales unit	1
Unit of quantity	Piece
Weight	1.1 kg
Weight unit	kg/100 pc.


Technical data sheet

Cover plate, Telitank T12L, round installation opening for EKR device

Item number: 7408172



Dimensions

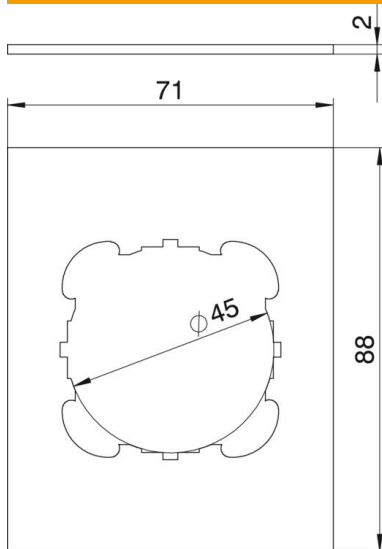

Length	88 mm
Width	71 mm
Height	2 mm

Technical data

Application	On-floor tank
Number of CEE/Perilex openings	0
Number of triple openings	0
Number of single openings	1
Number of oval openings	0
Number of square openings	0
Number of round openings	0
Number of double openings	0
Fastening type	Screw-on
Labelling panel	no
Blanking lid	no
Seal installation option	no
Suitable for labelling panel	no
Installation technology	Support clamp