


Technical data sheet

Cover plate, Telitank T12L, round installation opening for EKR device

Item number: 7408180

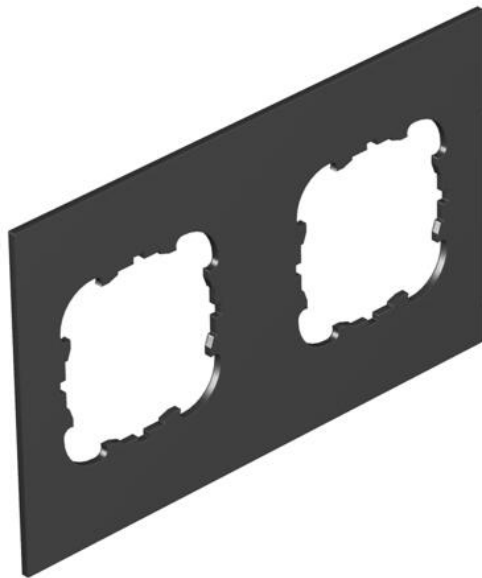

Cover plate with 2 perforations (Ø 45 mm) for 2 accessories with support ring or bracket, suitable for T12L lengthwise side (1/2 cover).



PVC Polyvinylchloride

Master data

Item number	7408180
Type	T12L P2S 9011
Description 1	Cover plate
Description 2	2x EK for T12L
Manufacturer	OBO
Dimension	142x88mm
Colour	Graphite black; RAL 9011
Material	Polyvinylchloride
Smallest sales unit	1
Unit of quantity	Piece
Weight	2.21 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0932 kg CO2e / 1 Piece


Technical data sheet

Cover plate, Telitank T12L, round installation opening for EKR device

Item number: 7408180



Dimensions

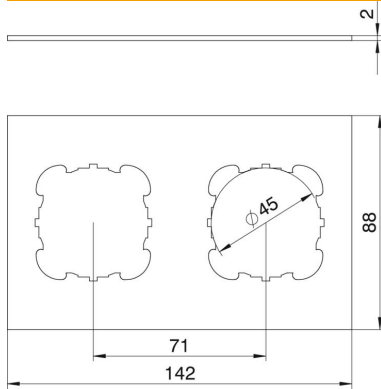

Length	88 mm
Width	142 mm
Height	2 mm

Technical data

Application	On-floor tank
Number of CEE/Perilex openings	0
Number of triple openings	0
Number of single openings	2
Number of oval openings	0
Number of square openings	0
Number of round openings	0
Number of double openings	0
Fastening type	Screw-on
Labelling panel	no
Blanking lid	no
Seal installation option	no
Suitable for labelling panel	no
Installation technology	Support clamp