


# Technical data sheet

Cover plate, Telitank T12L, round installation opening for EKR device

Item number: 7408196

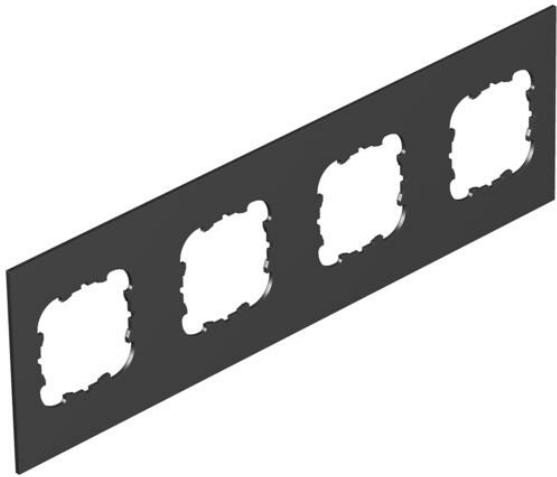

Cover plate with 4 perforations (Ø 45 mm) for four accessories with support ring or bracket, suitable for T12L lengthwise side (1/1 cover).



**PVC** Polyvinylchloride

## Master data

Item number	7408196
Type	T12L P4S 9011
Description 1	Cover plate
Description 2	4x EK for T12L
Manufacturer	OBO
Dimension	284x88mm
Colour	Graphite black; RAL 9011
Material	Polyvinylchloride
Smallest sales unit	1
Unit of quantity	Piece
Weight	4.42 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1883 kg CO2e / 1 Piece


# Technical data sheet

Cover plate, Telitank T12L, round installation opening for EKR device

Item number: 7408196



## Dimensions

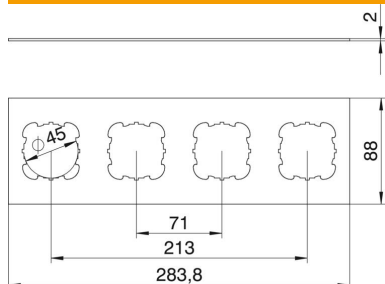

Length	88 mm
Width	284 mm
Height	2 mm

## Technical data

Application	On-floor tank
Number of CEE/Perilex openings	0
Number of triple openings	0
Number of single openings	4
Number of oval openings	0
Number of square openings	0
Number of round openings	0
Number of double openings	0
Fastening type	Screw-on
Labelling panel	no
Blanking lid	no
Seal installation option	no
Suitable for labelling panel	no
Installation technology	Support clamp