


# Technical data sheet

Cover plate, Telitank T4B, round installation opening for EK device

Item number: 7408252

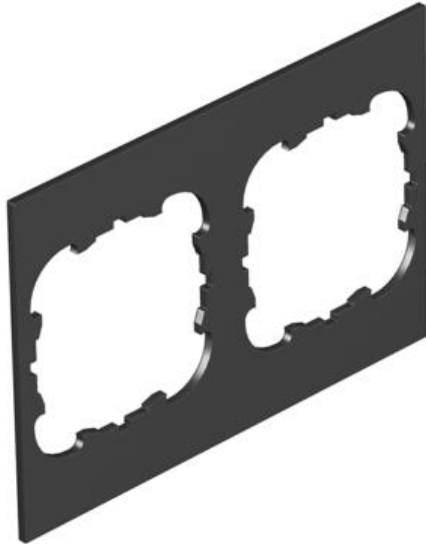

Cover plate with 2 perforations (Ø 45 mm) for two accessories with support clamp (EK version), suitable for T4B lengthwise side (1/2 cover).



**PVC** Polyvinylchloride

## Master data

Item number	7408252
Type	T4B P3S 9011
Description 1	Cover plate
Description 2	2x EK for T4B
Manufacturer	OBO
Dimension	110x77mm
Colour	Graphite black; RAL 9011
Material	Polyvinylchloride
Smallest sales unit	1
Unit of quantity	Piece
Weight	1.14 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0631 kg CO2e / 1 Piece

# Technical data sheet

Cover plate, Telitank T4B, round installation opening for EK device


Item number: 7408252



## Dimensions



Length	77 mm
Width	110 mm
Height	2 mm

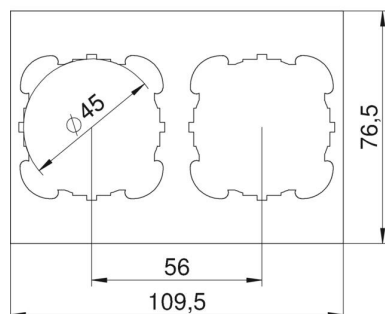

## Technical data

Application	On-floor tank
Number of CEE/Perilex openings	0
Number of triple openings	0
Number of single openings	2
Number of units	2
Number of oval openings	0
Number of square openings	0
Number of round openings	0
Number of double openings	0
Fastening type	Lockable
Labelling panel	no
Blanking lid	no
Suitable for labelling panel	no
Installation technology	Support clamp