

# Technical data sheet

## Cover plate, Telitank T4B, Modul 45® installation opening

Item number: 7408276



Cover plate with rectangular opening for a double Modul 45 socket, suitable for T4B lengthwise side (1/1 cover).



PA Polyamide

### Master data

Item number	7408276
Type	T4B P7 9011
Description 1	Cover plate
Description 2	double Modul 45 for T4B
Manufacturer	OBO
Dimension	110x77mm
Colour	Graphite black; RAL 9011
Material	Polyamide
Smallest sales unit	1
Unit of quantity	Piece
Weight	1.648 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0857 kg CO2e / 1 Piece


# Technical data sheet

Cover plate, Telitank T4B, Modul 45® installation opening

Item number: 7408276



## Dimensions

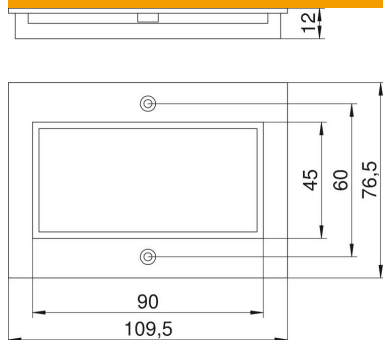

Length	77 mm
Width	110 mm
Height	12 mm

## Technical data

Application	On-floor tank
Number of CEE/Perilex openings	0
Number of triple openings	0
Number of single openings	0
Number of units	2
Number of oval openings	0
Number of square openings	0
Number of round openings	0
Number of double openings	1
Fastening type	Screw-on
Labelling panel	no
Suitable for labelling panel	no
Device type	Grid M45
Installation technology	Grid M45