

# Technical data sheet

## Telitank T4L

Item number: 7408300



Raised height installation unit for the installation of four individual accessories.  
Designed for use only on AIK systems.



**PA** Polyamide

| Master data                        |                          |  |
|------------------------------------|--------------------------|--|
| Item number                        | 7408300                  |  |
| Type                               | T4L00C 9011              |  |
| Description 1                      | Telitank                 |  |
| Manufacturer                       | OBO                      |  |
| Dimension                          | 225x125x125              |  |
| Colour                             | Graphite black; RAL 9011 |  |
| Material                           | Polyamide                |  |
| Smallest sales unit                | 1                        |  |
| Unit of quantity                   | Piece                    |  |
| Weight                             | 57.2 kg                  |  |
| Weight unit                        | kg/100 pc.               |  |
| CO2 Footprint (GWP) Cradle-to-Gate | 2,3745 kg CO2e / 1 Piece |  |


# Technical data sheet

## Telitank T4L

Item number: 7408300



### Dimensions

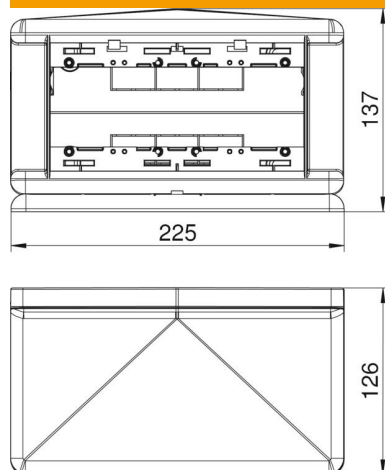

|        |        |
|--------|--------|
| Length | 225 mm |
| Width  | 126 mm |
| Height | 137 mm |

### Technical data

|                                           |            |
|-------------------------------------------|------------|
| Number of installable devices             | 4          |
| Number of installable devices, front side | 2          |
| Version for                               | Horizontal |
| Suitable for wet care                     | yes        |
| Suitable for standard switch material     | yes        |