


# Technical data sheet

## Telitank T8NL

Item number: 7408498

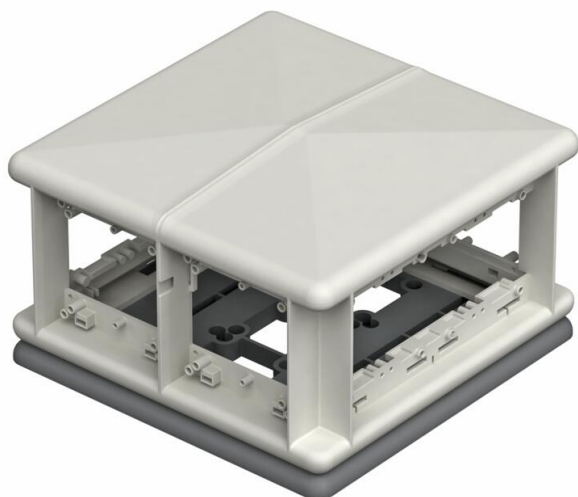

Raised-height installation unit for the installation of eight individual accessories with a support ring or support bracket on four sides. The current types (4 + 4) are separated using a partition. When multiple accessories are used, the connection capacity can be increased. Screw fixing groove for accessories: 60 mm, vertical.



PA Polyamide

### Master data

Item number	7408498
Type	T8NL 00C 7035
Description 1	Telitank
Manufacturer	OBO
Dimension	225x225x125
Colour	Light grey; RAL 7035
Material	Polyamide
Smallest sales unit	1
Unit of quantity	Piece
Weight	123.33 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	3,8071 kg CO2e / 1 Piece


# Technical data sheet

Telitank T8NL

Item number: 7408498



## Dimensions

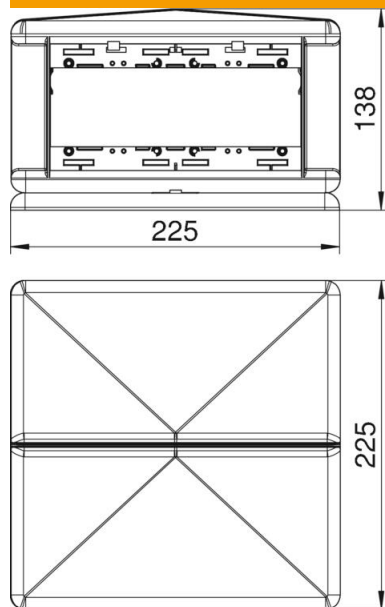

Length	225 mm
Width	225 mm
Height	138 mm

## Technical data

Number of installable devices	8
Number of installable devices, rear side	2
Number of installable devices, front side	2
Version for	Horizontal
Suitable for wet care	yes
Suitable for standard switch material	yes