


Technical data sheet

Pipe sleeve with 4 fastening straps

Item number: 7202205

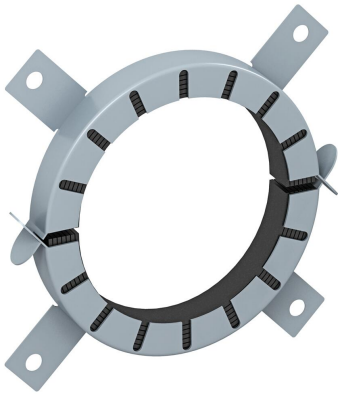

Pipe sleeve for combustible pipes.

If there is a fire, fire protection inserts inside the sheet steel housing expand, exerting a very great pressure onto the burning thermoplastic pipes. For interior application. Fastening with anchors of M6 threaded rods up to size 75 mm, then M8.




Intumescent material

Master data

Item number	7202205
Description 1	Pipe sleeve
Description 2	for combustible pipes
Manufacturer	OBO
Dimension	Ø75mm
Colour	Grey
Material	Intumescent material
Smallest sales unit	1
Unit of quantity	Piece
Weight	19 kg
Weight unit	kg/100 pc.

Dimensions

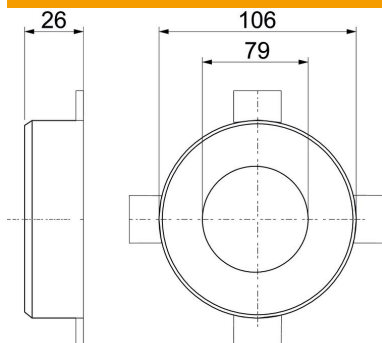

Length	106 mm
Width	106 mm
Height	26 mm
Dimension d	79 mm
Dimension d min.	106 mm
Dimension h	26 mm

Technical data sheet

Pipe sleeve with 4 fastening straps

Item number: 7202205



Technical data

Shape	Round
For pipe diameter, max.	77 mm
For pipe diameter, min.	75 mm
Collar lock	Connector
With fastening material	no
Accessories required	yes