


Technical data sheet

Pipe sleeve with 4 fastening straps

Item number: 7202206

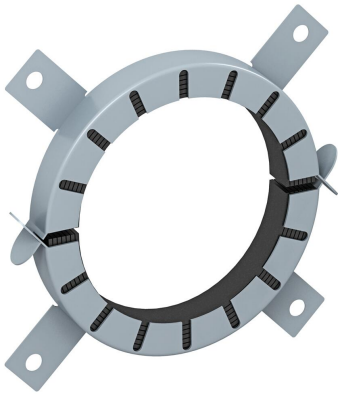

Pipe sleeve for combustible pipes.

If there is a fire, fire protection inserts inside the sheet steel housing expand, exerting a very great pressure onto the burning thermoplastic pipes. For interior application. Fastening with anchors of M6 threaded rods up to size 75 mm, then M8.




Intumescent material

Master data

Item number	7202206
Type	TCX-090
Description 1	Pipe sleeve
Description 2	for combustible pipes
Manufacturer	OBO
Dimension	Ø90mm
Colour	Grey
Material	Intumescent material
Smallest sales unit	1
Unit of quantity	Piece
Weight	37 kg
Weight unit	kg/100 pc.

Dimensions

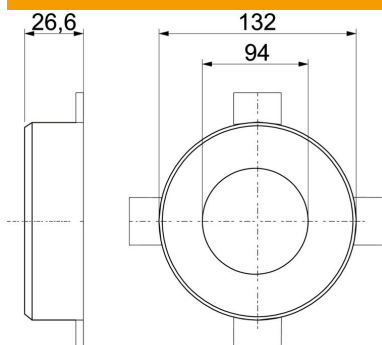

Length	132 mm
Width	132 mm
Height	26.6 mm
Dimension d	94 mm
Dimension d min.	132 mm
Dimension h	26.6 mm

Technical data sheet

Pipe sleeve with 4 fastening straps

Item number: 7202206



Technical data

Shape	Round
For pipe diameter, max.	92 mm
For pipe diameter, min.	90 mm
Collar lock	Connector
With fastening material	no
Accessories required	yes