

Technical data sheet

UDHOME2 floor socket, with stainless steel lid, freely
equippable

Item number: 7427019



Square floor socket for use in dry-care cavity and screed floors in indoor areas. Installation housing with pre-marked insertion openings for pipes (M25). Cover adjustable to top edge of floor covering using four height-adjustment supports. The minimum installation depth is 95 mm, the height-adjustment range +20 mm.

Up to two Modul45® sockets can be installed. In addition, up to two modular data modules (Keystones) can be installed with optional mounting supports.

Surfaces visible in the floor covering made of brushed stainless steel.

The load-bearing capacity of 15 kN is only guaranteed when in an unused state.



A2 Stainless steel

Master data

Item number	7427019
Description 1	Floor socket, complete
Description 2	empty, for 2 Modul45
Manufacturer	OBO
Material	Stainless steel
Smallest sales unit	1
Unit of quantity	Piece
Weight	150 kg
Weight unit	kg/100 pc.


Technical data sheet

UDHOME2 floor socket, with stainless steel lid, freely
equippable


Item number: 7427019



Dimensions

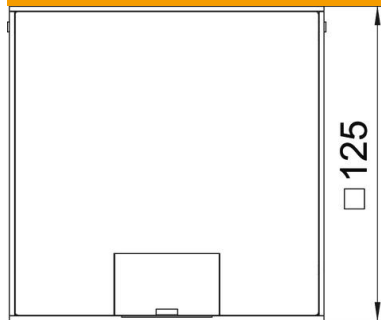

Dimension h 95 mm

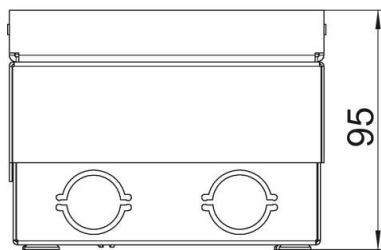

Technical data

Version for	Square
Cable outlet version	Swivellable cord outlet
Floor care	Dry
Floor height, max.	115 mm
Floor height, min.	95 mm
Suitable for raised floor installation	no
Suitable for screed-flush closed underfloor ducts	no
Suitable for screed-covered underfloor ducts	no
Suitable for cavity floor installation	yes
Suitable for wet care	no
Suitable for underfloor ducts	no
Length of external dimensions	125 mm
Length of installation dimensions	125 mm
With floor covering recess	no
Height-adjustment range, max.	115 mm
Height-adjustment range, min.	95 mm
Opening mechanism	Tool