

# Technical data sheet

## UDHOME2 floor socket, with tube body, double NF, stainless steel

Item number: 7368411



Square floor socket for use in wet-care cavity and screed floors in indoor areas. Cable exit for height-adjustable tube body. Installation housing with pre-marked insertion openings for pipes (M20/M25). Cover adjustable to top edge of floor covering using four height-adjustment supports. The minimum installation depth is 110 mm, the height-adjustment range is +25 mm. The load-bearing capacity of 15 kN is only guaranteed when in an unused state.



The scope of delivery contains a double NF socket. Up to two modular data sockets (Keystones) can be installed with optional mounting supports.



A2 Stainless steel

### Master data

Item number	7368411
Description 1	Floor socket, complete
Description 2	w. tube body, double NF socket
Manufacturer	OBO
Dimension	140x140x110
Material	Stainless steel
Smallest sales unit	1
Unit of quantity	Piece
Weight	323 kg
Weight unit	kg/100 pc.


# Technical data sheet

UDHOME2 floor socket, with tube body, double NF, stainless steel

Item number: 7368411



## Dimensions

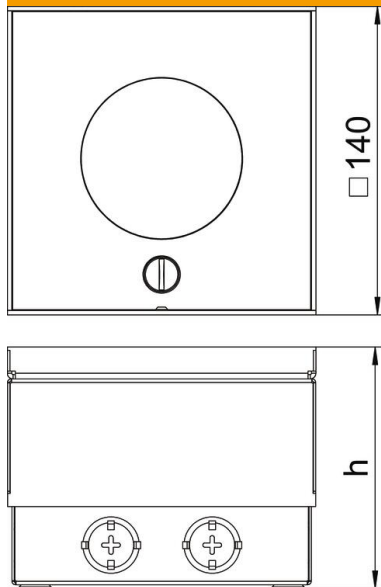

Length	140 mm
Width	140 mm
Dimension h	110 mm

## Technical data

Number of mounting boxes	1
Version for	Square
Cable outlet version	Lowerable tube body
Floor covering protection frame	no
Floor care	Wet
Floor height, max.	130 mm
Floor height, min.	110 mm
Suitable for raised floor installation	yes
Suitable for cavity floor installation	yes
Suitable for wet care	yes
Suitable for underfloor ducts	yes
Length of external dimensions	140 mm
Length of installation dimensions	140 mm
With floor covering recess	no
Opening mechanism	Sash lock