

# Technical data sheet

UDHOME4 floor box, with I4 mounting support, freely  
equippable, stainless steel  
Item number: 7427074



Square floor box for four installation devices of Italian design, for use in dry-care cavity and screed floors for indoor use. Installation housing with pre-marked insertion openings for pipelines (M25). Cover adjustable to top edge of floor covering using four height-adjustment supports. 15 mm floor covering recess in the hinged cover. The minimum installation depth is 110 mm, the height-adjustment range + 30 mm.

The scope of delivery contains a mounting support.

Surfaces made of stainless steel and visible in the floor covering.



A2 Stainless steel

## Master data

Item number	7427074
Type	UDHOME4 2V I4
Description 1	Floor box, complete
Description 2	for 4 installation devices
Manufacturer	OBO
Dimension	198x198x110
Material	Stainless steel
Smallest sales unit	1
Unit of quantity	Piece
Weight	364 kg
Weight unit	kg/100 pc.




# Technical data sheet


UDHOME4 floor box, with I4 mounting support, freely  
equippable, stainless steel  
Item number: 7427074



## Dimensions

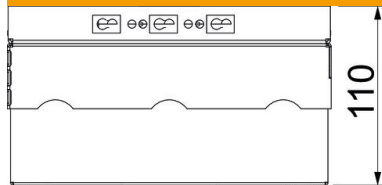

Length	202 mm
Width	202 mm

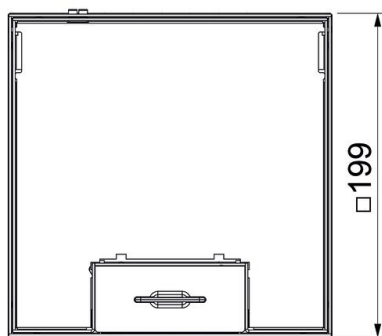

## Technical data

Cable outlet version	Swivellable cord outlet
Screed height, max.	130 mm
Screed height, min.	110 mm
Floor height, max.	140 mm
Floor height, min.	110 mm
Length of external dimensions	199 mm
Length of installation dimensions	202 mm
Height-adjustment range, max.	140 mm
Height-adjustment range, min.	110 mm
Protection rating (IP) when used	IP20
Protection rating (IP) when unused	IP40
Protection rating IK code	IK10
Opening mechanism	Handle
Floor covering thickness	15 mm