

Technical data sheet

UDHOME4 floor box, with universal support UT3 45 3, triple
NF, stainless steel
Item number: 7427224



Square floor box for use in dry-cleaned cavity and screed floors for indoor use. Installation housing with pre-marked insertion openings for pipes (M25). Cover adjustable to top edge of floor covering using four height-adjustment supports. 15 mm floor covering recess in the hinged cover. The minimum installation depth is 95 mm, the height-adjustment range + 30 mm.

The scope of delivery contains two universal supports UT3 45 3 and one triple NF socket. Up to three additional M45 devices can be installed.



A2 Stainless steel

Master data


| | |
|------------------------------------|--------------------------|
| Item number | 7427224 |
| Type | UDHOME4 2V UT N |
| Description 1 | Floor box, complete |
| Description 2 | triple NF socket |
| Manufacturer | OBO |
| Material | Stainless steel |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 413 kg |
| Weight unit | kg/100 pc. |
| CO2 Footprint (GWP) Cradle-to-Gate | 18,0129 kg COe / 1 Piece |

Technical data sheet


UDHOME4 floor box, with universal support UT3 45 3, triple NF, stainless steel
Item number: 7427224



Dimensions

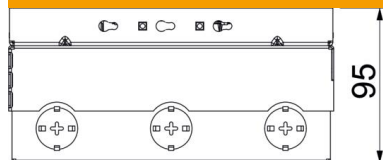

| | |
|--------|--------|
| Length | 202 mm |
| Width | 202 mm |

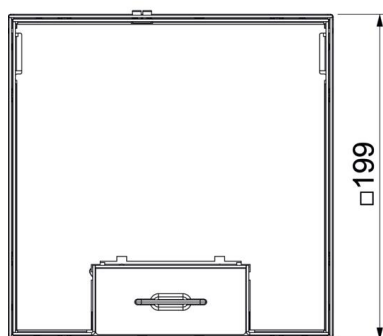

Technical data

| | |
|--|-------------------------|
| Number of mounting boxes | 2 |
| Version for | Square |
| Cable outlet version | Swivellable cord outlet |
| Equipment | 2 UT3, triple LF socket |
| Floor covering protection frame | no |
| Cover version | Floor covering recess |
| Screed height, max. | 110 mm |
| Screed height, min. | 95 mm |
| Floor height, max. | 125 mm |
| Floor height, min. | 95 mm |
| Suitable for raised floor installation | no |
| Suitable for cavity floor installation | yes |
| Suitable for wet care | no |
| Suitable for underfloor ducts | no |
| Length of external dimensions | 199 mm |
| Length of installation dimensions | 202 mm |
| With floor covering recess | yes |
| Height-adjustment range, max. | 125 mm |
| Height-adjustment range, min. | 95 mm |
| Protection rating (IP) when used | IP20 |
| Protection rating (IP) when unused | IP40 |
| Protection rating IK code | IK10 |
| Opening mechanism | Handle |
| Floor covering thickness | 15 mm |