

Technical data sheet

Floor box UDHOME4 with brush bar, stainless steel, with
FLF support, cover can be covered

Item number: 7427256



Square installation unit for use in dry-care cavity and screed floors for indoor use.

Installation housing with pre-marked insertion openings for pipes (M25). Cover adjustable to the top edge of the floor covering using four height-adjustment supports. The minimum installation depth is 95 mm, the height adjustment range is +30 mm.

Flushfloor cable outlet through brush bar.

Device support made of galvanised sheet steel for 6x FLF 3/5 or 4x FLF 3/5 and 1x FLF 6/5.

Lid can be covered with floor covering, 15 mm.

A2 Stainless steel

Master data

Item number	7427256
Type	UDHOME4 2V U PE
Description 1	Floor box, complete
Description 2	for FLF devices
Manufacturer	OBO
Material	Stainless steel
Smallest sales unit	1
Unit of quantity	Piece
Weight	373 kg
Weight unit	kg/100 pc.


Technical data sheet

Floor box UDHOME4 with brush bar, stainless steel, with FLF support, cover can be covered


Item number: 7427256



Dimensions

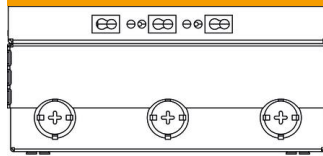

Length	202 mm
Width	202 mm

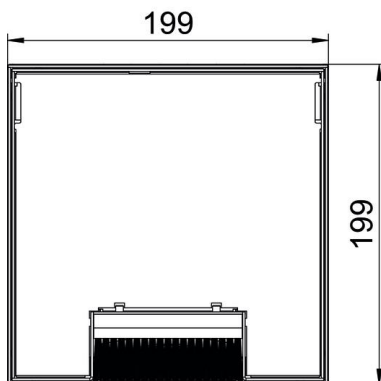

Technical data

Number of mounting boxes	2
Version for	Square
Cable outlet version	Brush bar
Equipment	FLF supports
Floor covering protection frame	no
Cover version	Floor covering recess
Screed height, max.	110 mm
Screed height, min.	95 mm
Floor height, max.	125 mm
Floor height, min.	95 mm
Suitable for raised floor installation	no
Suitable for cavity floor installation	yes
Suitable for wet care	no
Suitable for underfloor ducts	no
Length of external dimensions	199 mm
Length of installation dimensions	202 mm
With floor covering recess	yes
Height-adjustment range, max.	125 mm
Height-adjustment range, min.	95 mm
Protection rating (IP) when used	IP20
Protection rating (IP) when unused	IP40
Protection rating IK code	IK10
Floor covering thickness	15 mm