

# Technical data sheet

## Floor box UDHOME9, two double VDE, stainless steel

Item number: 7427308



Square floor box for use in dry-cleaned cavity and screed floors in indoor areas. Installation housing with pre-marked insertion openings for pipes (M25). With three UT4 universal supports and two double protective contact sockets. Cover adjustable to top edge of floor covering using four height-adjustment supports. The minimum installation depth is 95 mm, the height-adjustment range + 30 mm. The scope of supply contains three universal supports UT4 45 4 for direct mounting of Modul 45 devices. Of these, one is equipped with two double protective contact sockets in pure white.



Surfaces visible in the floor covering made of stainless steel.



A2 Stainless steel

### Master data

Item number	7427308
Type	UDHOME9 2V UT45V
Description 1	Floor box, complete
Description 2	two double VDE sockets
Manufacturer	OBO
Material	Stainless steel
Smallest sales unit	1
Unit of quantity	Piece
Weight	520 kg
Weight unit	kg/100 pc.


# Technical data sheet

## Floor box UDHOME9, two double VDE, stainless steel


Item number: 7427308



### Dimensions

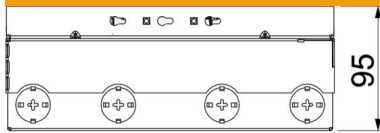

Length	246 mm
Width	246 mm

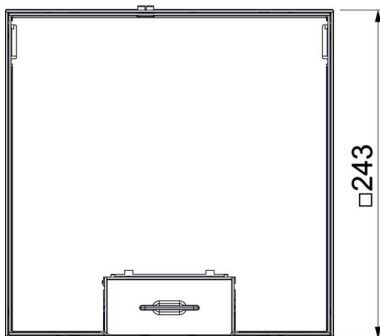

### Technical data

Cable outlet version	Swivellable cord outlet
Equipment	3 UT4, 2 double VDE socket
Cover version	Floor covering recess
Screed height, max.	110 mm
Screed height, min.	95 mm
Floor height, max.	125 mm
Floor height, min.	95 mm
Length of external dimensions	243 mm
Length of installation dimensions	246 mm
Height-adjustment range, max.	125 mm
Height-adjustment range, min.	95 mm
Protection rating (IP) when used	IP20
Protection rating (IP) when unused	IP40
Protection rating IK code	IK10
Opening mechanism	Handle
Floor covering thickness	15 mm