

# Technical data sheet

## Floor box UDHOME9, two double NF, stainless steel

Item number: 7427316



Square floor box for use in dry-cleaned cavity and screed floors for indoor use. Installation housing with pre-marked insertion openings for pipes (M25). Cover adjustable to top edge of floor covering using four height-adjustment supports. 15 mm floor covering recess in the hinged cover. The minimum installation depth is 95 mm, the height-adjustment range + 30 mm.

The scope of delivery contains 3 universal supports UT4 45 4 for direct mounting of Modul 45 devices. Of these, one is equipped with two double NF sockets in pure white.

Surfaces visible in the floor covering made of: Stainless steel, material 1.4301.



A2 Stainless steel

### Master data

Item number	7427316
Type	UDHOME9 2V UT N
Description 1	Floor box, complete
Description 2	two double NF sockets
Manufacturer	OBO
Material	Stainless steel
Smallest sales unit	1
Unit of quantity	Piece
Weight	520 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	24,976 kg COe / 1 Piece


# Technical data sheet

Floor box UDHOME9, two double NF, stainless steel


Item number: 7427316



## Dimensions

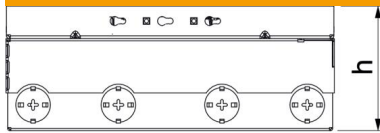

Length	246 mm
Width	246 mm

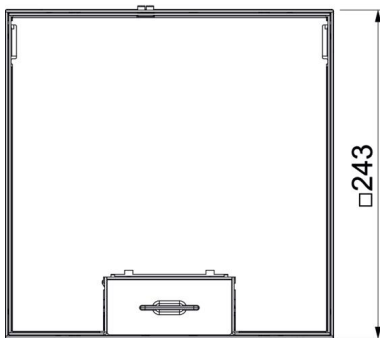

## Technical data

Cable outlet version	Swivellable cord outlet
Equipment	3 UT4, 2 double LF socket
Cover version	Floor covering recess
Screed height, max.	110 mm
Screed height, min.	95 mm
Floor height, max.	125 mm
Floor height, min.	95 mm
Length of external dimensions	243 mm
Length of installation dimensions	246 mm
Height-adjustment range, max.	125 mm
Height-adjustment range, min.	95 mm
Protection rating (IP) when used	IP20
Protection rating (IP) when unused	IP40
Protection rating IK code	IK10
Opening mechanism	Handle
Floor covering thickness	15 mm