

Technical data sheet

UDHOME9 floor box, two double VDE, stainless steel

Item number: 7427300



Square floor box for use in dry-cleaned cavity and screed floors in indoor areas. Installation housing with pre-marked insertion openings for pipes (M25). With three UT4 universal supports and two double sockets. Cover adjustable to top edge of floor covering using four height-adjustment supports. The minimum installation depth is 95 mm, the height-adjustment range + 30 mm.

The scope of supply contains three universal supports UT4 for installation of Modul 45® devices. One universal support is equipped with two double protective contact sockets in pure white. A further universal support is equipped with two cover plates for standard device installation and the third universal support is equipped with two blanking covers.

Surfaces visible in the floor covering made of stainless steel.



A2 Stainless steel

Master data

Item number	7427300
Type	UDHOME9 2V UT V
Description 1	Floor box, complete
Description 2	two double VDE sockets
Manufacturer	OBO
Material	Stainless steel
Smallest sales unit	1
Unit of quantity	Piece
Weight	520.5 kg
Weight unit	kg/100 pc.


Technical data sheet

UDHOME9 floor box, two double VDE, stainless steel


Item number: 7427300



Dimensions

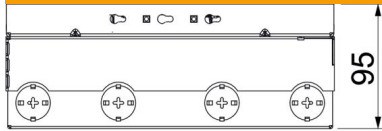

Length	246 mm
Width	246 mm

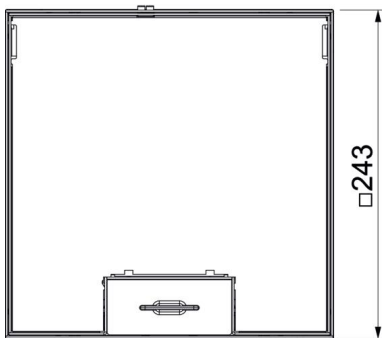

Technical data

Cable outlet version	Swivellable cord outlet
Equipment	3 UT4, 2 double VDE socket
Cover version	Floor covering recess
Screed height, max.	110 mm
Screed height, min.	95 mm
Floor height, max.	125 mm
Floor height, min.	95 mm
Suitable for underfloor ducts	no
Length of external dimensions	243 mm
Length of installation dimensions	246 mm
With floor covering recess	yes
Height-adjustment range, max.	125 mm
Height-adjustment range, min.	95 mm
Protection rating (IP) when used	IP20
Protection rating (IP) when unused	IP40
Protection rating IK code	IK10
Opening mechanism	Handle
Floor covering thickness	15 mm