

# Technical data sheet

Floor box UDHOME9 with brush bar, stainless steel, with  
FLF support, cover can be covered  
Item number: 7427332



Square installation unit for use in dry-care cavity and screed floors for indoor use.

Installation housing with pre-marked insertion openings for pipes (M25). Cover adjustable to the top edge of the floor covering using four height-adjustment supports. The minimum installation depth is 95 mm, the height adjustment range is +30 mm.

Flushfloor cable outlet through brush bar.

Device support made of galvanised sheet steel for 9x FLF 3/5.

Lid can be covered with floor covering, 15 mm.

A2    Stainless steel

Master data		
Item number	7427332	
Type	UDHOME9 2V U PE	
Description 1	Floor box, complete	
Description 2	for FLF devices	
Manufacturer	OBO	
Material	Stainless steel	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	530 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	25,0101 kg COe / 1 Piece	


# Technical data sheet

Floor box UDHOME9 with brush bar, stainless steel, with  
FLF support, cover can be covered

Item number: 7427332



## Dimensions

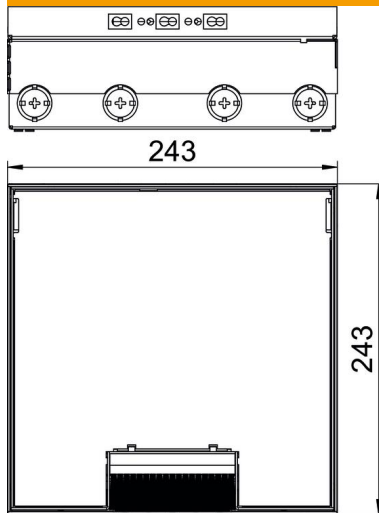

Length	246 mm
Width	246 mm

## Technical data

Cable outlet version	Brush bar
Equipment	FLF supports
Cover version	Floor covering recess
Screed height, max.	110 mm
Screed height, min.	95 mm
Floor height, max.	125 mm
Floor height, min.	95 mm
Length of external dimensions	243 mm
Length of installation dimensions	246 mm
Height-adjustment range, max.	125 mm
Height-adjustment range, min.	95 mm
Protection rating (IP) when used	IP20
Protection rating (IP) when unused	IP40
Protection rating IK code	IK10
Floor covering thickness	15 mm