

Technical data sheet

Underfloor box UDSR9 for PVC duct

Item number: 7400358



Underfloor outlet box with fixed, unchangeable installation opening of \varnothing 305 mm for an installation unit of nominal size R9. The mounting opening is created using the screed protection cover contained in the scope of supply. The underfloor box possesses installation openings for three single-compartment PVC ducts of nominal size 60 x 25 and 90 x 35 on all four sides. The box is principally suited for use in floor structures in cement screed with a structure height of up to 95 mm.



St Steel

FS Strip galvanized

Master data

Item number	7400358
Type	UDSPD 9035 R9
Description 1	Underfloor box
Description 2	for GESR9
Manufacturer	OBO
Dimension	364x364x97
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	236 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	11,3714 kg CO2e / 1 Piece

 
Technical data sheet

Underfloor box UDSR9 for PVC duct


Item number: 7400358



Dimensions



Length	364 mm
Width	364 mm
Height	96 mm
Dimension d Ø	305 mm

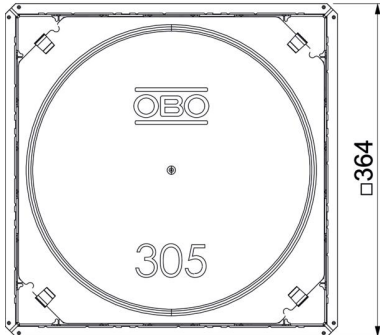

Technical data

Floor plate	yes
Seal installation option	yes
Installation opening for flush-mount unit	Round
Screed height, max.	95 mm
Screed height, min.	65 mm
Suitable for screed-covered underfloor ducts	yes
Trunking width, max.	90 mm
Trunking width, min.	60 mm
Trunking height, max.	35 mm
Duct height, min.	25 mm
Nominal size for device installation units	R9