


Technical data sheet

Underfloor box UDS9 for installation pipe and metal duct

Item number: 7400353

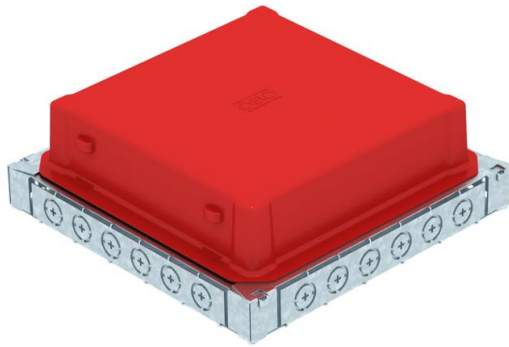

Underfloor outlet box with fixed, unchangeable installation opening for an installation unit of nominal size 9. The mounting opening is created using the screed protection cover contained in the scope of supply. The underfloor socket possesses installation openings for a 2 or 3-compartment sheet steel underfloor duct of nominal size 25038 as well as six M20 or M25 installation pipes on all four sides. The sockets are principally suited for use in floor structures in cement screed with a structure height of up to 105 mm.



St	Steel
FS	Strip galvanized

Master data

Item number	7400353
Description 1	Underfloor box
Description 2	for GES9
Manufacturer	OBO
Dimension	308x308x92
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	226 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	7,9691 kg COe / 1 Piece



Technical data sheet

Underfloor box UDS9 for installation pipe and metal duct

Item number: 7400353



Dimensions

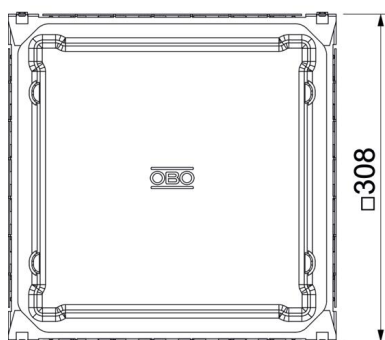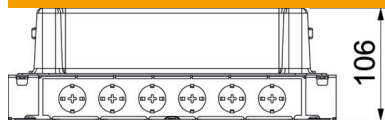

Technical data

Number of installable devices	1
Floor plate	no
Lowerable to be flush-floor	no
Seal installation option	no
Installation opening for on-floor tank	no
Installation opening for flush-mount unit	Square
Decouplable	no
Screed height, max.	100 mm
Screed height, min.	65 mm
For pipe connection	yes
Suitable for screed-flush closed underfloor ducts	no
Suitable for screed-covered underfloor ducts	no
Suitable for underfloor ducts	no
Trunking width, max.	250 mm
Trunking width, min.	250 mm
Trunking height, max.	38 mm
Duct height, min.	38 mm
Nominal size	380 mm
Nominal size for device installation units	9
Height-adjustment range, max.	106 mm
Height-adjustment range, min.	62 mm
Protection rating (IP) when used	IP20