

# Technical data sheet

## Complete solution, GES9 service outlet

Item number: 7427470



Square installation unit with cord outlet for use in dry-care cavity floors and screed floors for indoor use, consisting of an installation housing and GES9-3 service outlet (color ) with two UT4 universal supports. Installation housing with pre-marked insertion openings for pipelines (M25), adjustable to top edge of screed. In the as-delivered state, the installation housing is closed with a blanking lid. After screed work, the service outlet can be inserted in the created mounting opening. 3, 5, 8 or 10 mm floor covering recess in the hinged cover of the service outlet.

The minimum installation depth is 72 mm including floor covering, the height adjustment range +30 mm.

Up to 12 individual Modul 45® devices can be installed.



PA Polyamide

### Master data

Item number	7427470
Type	UD GES9-3 7011
Description 1	Service outlet
Description 2	with installation housing
Manufacturer	OBO
Colour	Iron grey; RAL 7011
Material	Polyamide
Smallest sales unit	1
Unit of quantity	Piece
Weight	340 kg
Weight unit	kg/100 pc.


# Technical data sheet

Complete solution, GES9 service outlet

Item number: 7427470



## Dimensions

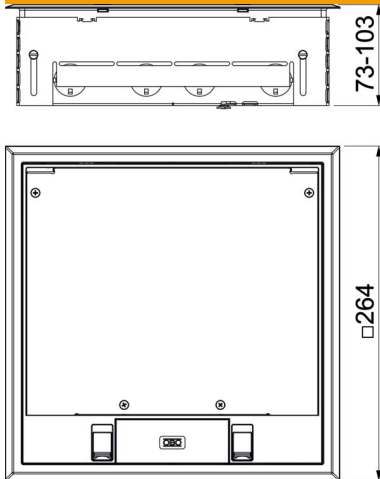

## Technical data

Cable outlet version	Swivellable cord outlet
Screed height, max.	100 mm
Screed height, min.	72 mm
Floor height, max.	100 mm
Floor height, min.	72 mm
Protection rating (IP) when used	IP20
Protection rating (IP) when unused	IP40
Protection rating IK code	IK08
Opening mechanism	Locking slider
Floor covering thickness	5 mm