

Technical data sheet

UP Flush-mounted electronics box 46, rectangular, with clamping area to the side

Item number: 2003725



Flush-mounted electronics box, with side clamping space, rectangular shape, for use in masonry with an installation depth of at least 50 mm.

- Connector with bayonet lock, couplable on both sides
 - 10 combination pipe entries of Ø 20 and 25 mm
 - 2 entries up to Ø 20 mm in the base
 - 4 entries for flat cables/ribbon cables
 - 4 x 3 screw domes
- Tested according to DIN EN 60670-1, DIN EN 60670-22 and DIN 49073-1.



PP Polypropylene

Master data

Item number	2003725
Type	UE 46
Description 1	UP Flush-mount. electronic box
Description 2	with lateral terminal area
Available from	01.10.2021
Manufacturer	OBO
Dimension	Ø60xH50x114
Colour	Jet black
Material	Polypropylene
Smallest sales unit	10
Unit of quantity	Piece
Weight	4.3 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1666 kg COe / 1 Piece


Technical data sheet

UP Flush-mounted electronics box 46, rectangular, with
clamping area to the side

Item number: 2003725



Dimensions

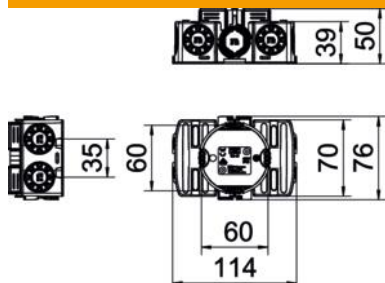

Length	114 mm
Width	76 mm
Height	50 mm

Technical data

No. of entries	16
Type of insertion	NYM cables, data cables and corrugated pipes
Type of housing penetration	Break-out opening
Version for	Single
Type	Electrics socket
Device fixing	Screws ,
Cover	Without
Cover fastening	Screws ,
Entry from rear	yes
Flame-resistant	acc. to VDE 0471/IEC 60695-2-11, test temperature 650°C
Shape	Rectangular
for pipe diameter	20/25 mm
Accessory screw clearance	60 mm
Halogen-free	yes
Combination entries Ø 20 / 25 mm	10
With nail strap	no
With bolts	yes
Nominal cross-section, max.	2.5 mm ²
Nominal cross-section, min.	1.5 mm ²
Pipe entries Ø 20 mm	2
Impact-resistant	yes
Protection rating	IP30
Airtight	no
Rated voltage	400 V