

Technical data sheet

UP Flush-mounted electronics box 66, airtight

Item number: 2003727



Flush-mounted electronics box, with additional clamping space and airtight membrane entries, for use in masonry with an installation depth of at least 67 mm.

- With 4 couplable connectors with bayonet lock
 - 4 combination pipe entries of Ø 20 and 25 mm
 - 4 entries up to Ø 20 mm
 - 14 entries up to Ø 11 mm
 - 2 entries up to Ø 20 mm in the base
 - Partition for different voltages, with break-out openings
 - 4 x 3 screw domes
- Tested according to DIN EN 60670-1, DIN EN 60670-22 and DIN 49073-1.



PP/TPE Polypropylene / Thermoplastic elastomer

Master data

Item number	2003727
Type	UE 66-L
Description 1	UP Flush-mount. electronic box
Description 2	with device screws, airtight
Available from	01.10.2021
Manufacturer	OBO
Dimension	Ø60xH67x148
Colour	deep black / blue grey
Material	Polypropylene / Thermoplastic elastomer
Smallest sales unit	10
Unit of quantity	Piece
Weight	6.6 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,2653 kg CO2e / 1 Piece


Technical data sheet

UP Flush-mounted electronics box 66, airtight

Item number: 2003727



Dimensions

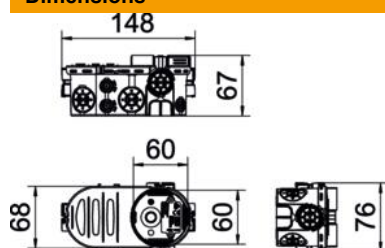

Length	148 mm
Width	76 mm
Height	67 mm

Technical data

No. of entries	24
Type of entry	NYM cables, data cables and corrugated pipes
Type of housing penetration	Insertion membrane
Version for	Single
Type	Device connection box
Device fixing	Screws ,
Cover	Without
Cover fastening	Screws ,
Entry from rear	yes
Flame-resistant	acc. to VDE 0471/IEC 60695-2-11, test temperature 650°C
Shape	Oval
for pipe diameter	20/25 mm
Halogen-free	yes
Combination entries Ø 20 / 25 mm	4
With nail strap	no
With bolts	yes
Nominal cross-section, max.	2.5 mm ²
Nominal cross-section, min.	1.5 mm ²
Pipe entries Ø 20 mm	6
Impact-resistant	no
Protection rating	IP30
Airtight	yes
Rated voltage	400 V