

Technical data sheet

Underfloor box UGE2 for installation pipe and metal duct

Item number: 7428062



Underfloor outlet box with fixed, unchangeable 106 x 182 mm installation opening for an installation unit of nominal size 2. The mounting opening is created using the screed protection cover contained in the scope of supply. The underfloor box has two openings for M20 conduit on the narrow sides. The underfloor box is suitable for screed floor constructions with height 70 mm up to 90 mm.



St

Steel

FS

Strip galvanized

Master data

Item number	7428062
Type	UGE 2C
Description 1	Underfloor box empty
Description 2	for GES2
Manufacturer	OBO
Dimension	240x150x88
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	74.1 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	3,2392 kg CO2e / 1 Piece


Technical data sheet

Underfloor box UGE2 for installation pipe and metal duct

Item number: 7428062



Dimensions

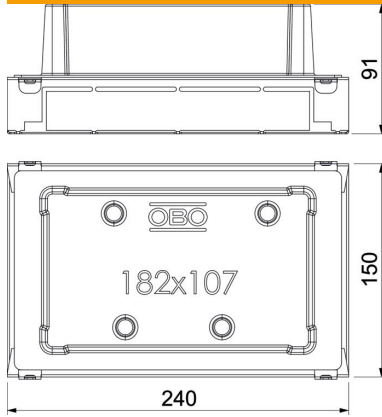

Length	240 mm
Width	150 mm
Height	91 mm

Technical data

Seal installation option	yes
Installation opening for flush-mount unit	Rectangular
Screed height, max.	90 mm
Screed height, min.	70 mm
Nominal size for device installation units	2